

Configuration details V6028NB (AC input)

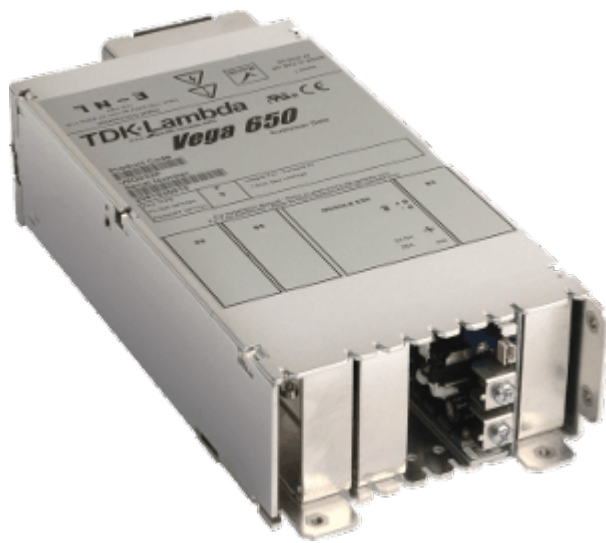


Photo of example product

[Product Page](#)[Related Products](#)

Part number	V6028NB
Product Description	V6FSS B/S 21.5D5SN 21.5D5SN
Total requested output power	645 W
Total output power	650 W
Approvals	C-UL-US, CE
Cooling	Forward air fan - end mount
Input	Screw
Earth leakage	1500µA maximum leakage current
Primary option	None
Dimensions (mm)	L:268.4 W:126.5 H:62.8mm (10.57 x 4.98 x 2.47in)

Module	B/S	D5	D5	B/S
Output 1	-	21.5V/15A	21.5V/15A	-
Output 2	-	-	-	-
Option	-	Inhibit, module good, remote sense and current share	Inhibit, module good, remote sense and current share	-
Connection	-	SCREW	SCREW	-

The view shown is of the output end of the supply.

Datasheet [Datasheet](#)

Created by: [TDK-Lambda UK Quick Product Finder](#), Version: - 092.003c