


Wiha Soft Grip Pliers & Cutters

Wiha Pliers & Cutters, professional quality at competitive prices. A wide selection covering most applications in which pliers & cutters are required.

Precision formed
64HRC
Cutting Edges
Jaws and
cutters induction
hardened

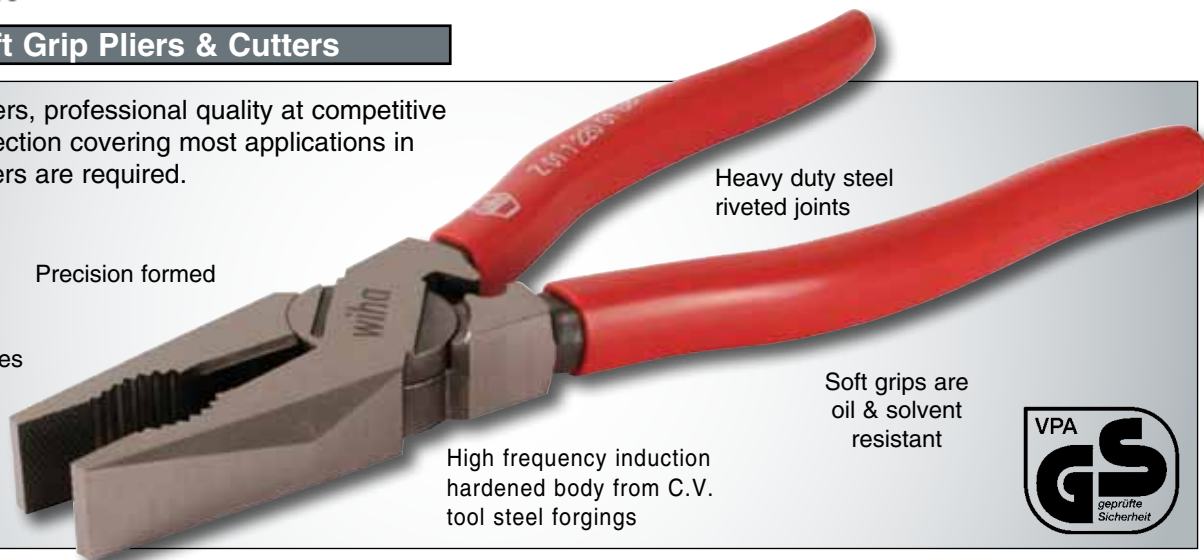

Heavy duty steel
riveted joints
Soft grips are
oil & solvent
resistant
High frequency induction
hardened body from C.V.
tool steel forgings



Lineman's Pliers With Crimpers

5-in-1 Lineman's Pliers



With Lower Crimping Jaw



32616 Lineman's Pliers "5-in-1" Professional Design

Deep cut radius conduit jaws for non-slip gripping. Extra long induction hardened precision matched 64HRC cutting edges. Lower crimping jaw accepts most standard non-insulated electrical connectors. Large head with square anvil surface on each side. Made from premium C70 tool steel forgings. Vinyl coated cushion grips for best user comfort.

Item	↔	↔	Cutting Capacity		
No.	mm	Inch	Copper AWG	Pkg.	lbs.
32616	225	9.0	#4	1	.88

Combination Pliers With Cutters



326 Combination Pliers With Cutters DIN ISO 5746

Extra long cutting edge for flat and round cables. Serrated jaws. Cutting edges additionally induction hardened to approx. 64HRC. C70 Special tool steel. For gripping and holding as well as cutting soft and hard wires and cables. Soft vinyl grips, oil & solvent resistant.

Item	↔	↔	Cutting Capacity		
No.	mm	Inch	Copper AWG	Pkg.	lbs.
32603	160	6.3	#10	1	.41
32606	180	7.0	#9	1	.50
32609	200	8.0	#8	1	.63

High Leverage Combination Pliers



326 High Leverage Heavy Duty Combination Pliers DIN ISO 5746

Extra long cutting edge for flat and round cables. Serrated jaws. Cutting edges additionally induction hardened to approx. 64HRC. C70 Special tool steel forgings. Use For gripping, pulling & holding as well as cutting soft, hard & piano wires and cables. Soft vinyl grips are oil & solvent resistant.

Item	↔	↔	Cutting Capacity		
No.	mm	Inch	Copper AWG	Pkg.	lbs.
32612	200	8.0	#4	1	.61
32615	225	9.0	#4	1	.78

Long Nose Pliers With Cutters



326 Long Nose Pliers With Cutters DIN ISO 5745

Long nose pliers. Extra long cutters for flat and round cables. Serrated Jaws. Cutting edges additionally induction hardened to approx. 64HRC. Special C70 tool steel forgings. Soft vinyl grips are oil & solvent resistant.

Item	↔	↔	Cutting Capacity		
No.	mm	Inch	Copper AWG	Pkg.	lbs.
32618	160	6.3	#10	1	.28
32621	200	8.0	#8	1	.86