


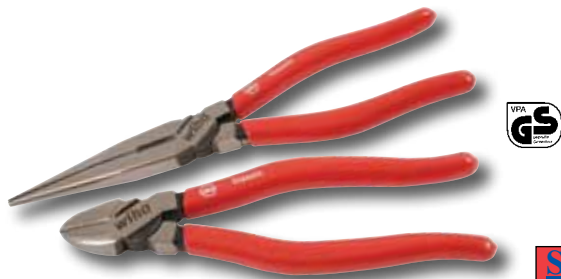
Wiha Soft Grip Pliers & Cutters



32698 3 Piece Pliers & Cutters Set


Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.

Item# 32698 Set Includes:	 lbs. 1.39
32606 - Combination Pliers	32642 - Diagonal Cutters
32618 - Long Nose Pliers	



32648 2 Piece Pliers & Cutters Set

Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.

Item# 32648 Set Includes:	 lbs. .78
32621 - Long Nose Pliers With Cutters - 8.0"	
32642 - Diagonal Cutters - 6.3"	



32610 Multipurpose Electrician's Heavy Duty Shears

High alloy carbon steel, hardened, burnished surface. Sturdy model, straight, very robust, micro-toothed cutting.

Item No.	mm	Inch	Pkg.	lbs.
32610	145	5.75	1	.05

32611 SoftGrip Electrician's & Craftsman Shears

Item No.	mm	Inch	Pkg.	lbs.
32611	145	5.75	1	.05

Wiha Soft Grip Nippers



326 High Leverage End Cutting Nippers DIN ISO 5749 Low wear lap joint, riveted and able to withstand high levels of load. Low force action, clean cutting. Long life cutting edges are achieved through additional induction hardening to approx. 60 HRC. Special C70 tool steel forgings hardened and tempered. Soft vinyl grips are oil & solvent resistant.

Item No.	mm	Inch	Cutting Capacity Copper AWG	Pkg.	lbs.
32657	160	6.3	#6	1	.41
32658	180	7.0	#6	1	.61
32659	200	8.0	#6	1	.75



326 Carpenter's End Nippers DIN ISO 9243

High cutting performance and reduced effort achieved through the precise formation of the cutting blade after assembly. Long life cutting edges achieved by additional induction hardening. Special C70 tool steel, hardened and tempered. Soft vinyl grips are oil & solvent resistant.

Item No.	mm	Inch	Pkg.	lbs.
32671	180	7.0	1	.62
32672	200	8.0	1	.86



326 Mason Nippers DIN ISO 9243

High cutting performance and reduced effort achieved through the precise formation of the cutting blade after assembly. Long life induction hardened cutting edges. Special C70 tool steel, hardened & tempered. Soft vinyl Grips are oil & solvent resistant.

Item No.	mm	Inch	Cutting Capacity Hard Wire AWG	Pkg.	lbs.
32674	220	8.75	#12	1	.76
32676	250	10.0	#12	1	.98
32678	280	11.0	#12	1	1.00
32680	300	12.0	#12	1	1.06