

0055 Door Switches



C0055RB ---



C0056RB ---

- ▶ Ratings up to 2A, 250V ac
- ▶ High temperature rating up to 125°C
- ▶ Long overtravel
- ▶ Choice of terminal orientation



RoHS

0055 & 0056
0.2(0.2)A 250Vac 25T125 5E4
(50,000 operations)

RoHS compliant

μ contact gap

Technical data on pages 4 & 5



C0055RB ---



C0056RB ---




ORDER FORMAT

C 0055 R B

TERMINAL CODE FUNCTION CODE ACTUATOR CODE BODY CODE

▶ TERMINAL	▶ FUNCTION	▶ ACTUATOR	▶ BODY	▶ OPTIONS
C 6.3 x 0.8 9.1	0055 ON - OFF (momentary OFF) 90° terminals	R 	B Panel cut-out Ø19.05 19.2 Panel thickness 0055 1.0 - 1.6 0056 1.0 - 2.6	Finish Gloss finish only Color White is standard Call factory for custom colors
H (0056 only) 4.8 x 0.8 9.1	0056 ON - OFF (momentary OFF) Straight terminals		Flange Ø24.1 6.6	

Dimensions (mm)
C0055RB

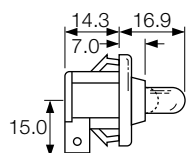

C0056RB

