

ELCO EUROPE (A DIVISION OF AVX LTD.) CONFIDENTIAL PROPRIETARY
THE DRAWING ON THIS PRINT AND INFORMATION THEREWITH ARE
PROPRIETARY TO ELCO EUROPE (A DIVISION OF AVX LTD.) AND
SHALL NOT BE USED OR DISCUSSED IN WHOLE OR IN PART
WITHOUT ELCO EUROPE'S WRITTEN CONSENT.




SEE TABLE		
AWM	2468	80°C
AWM	2468	80°C
AWM	2468	80°C

NOTES :-


1. INSULATION :- WHITE PVC, FLAME RETARDENT VW-1.
2. CONDUCTION :- 24AWG, TINNED COPPER, 11 STRANDS 0.16mmØ.
3. NUMBER OF WAYS, SEE TABLE.
4. MAXIMUM OPERATING TEMPERATURE 80°C.
5. VOLTAGE RATING 300v.
6. WIRE TO BE UL2468.
7. UL MARKING ON ALTERNATE WIRES.
8. SUPPLIED ON REELS, 305m PER REEL

PART NUMBER	NUMBER OF WAYS
90-2220-7360-02-000	2
90-2220-7360-03-000	3
90-2220-7360-04-000	4
90-2220-7360-05-000	5
90-2220-7360-06-000	6

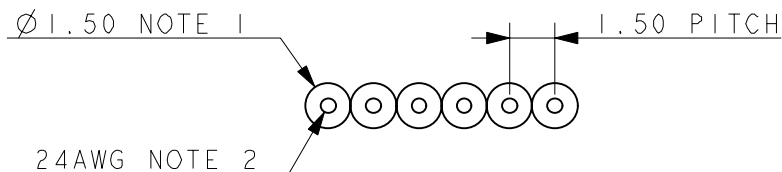

Elco Europe (A Division of AVX Ltd) CONFIDENTIAL PROPRIETY
The document on this print and information therewith are PROPRIETY
to Elco Europe (A Division of AVX Ltd) and shall not be copied
or disclosed in whole or in part without Elco Europe's written consent.

Release No.
History
1102838
25.07.2012
08.08.2012
28.08.2012

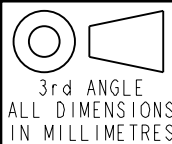

ELCO

© COPYRIGHT ELCO EUROPE
NOT TO BE DISCLOSED OR COPIED
WITHOUT WRITTEN PERMISSION

Drawn
N.C.H.

Size
AV

Description
RIBBON CABLE - 24AWG

Part Number
90-2220-7360-0X-000S

DATE
25-Jul-12

Issue
C