


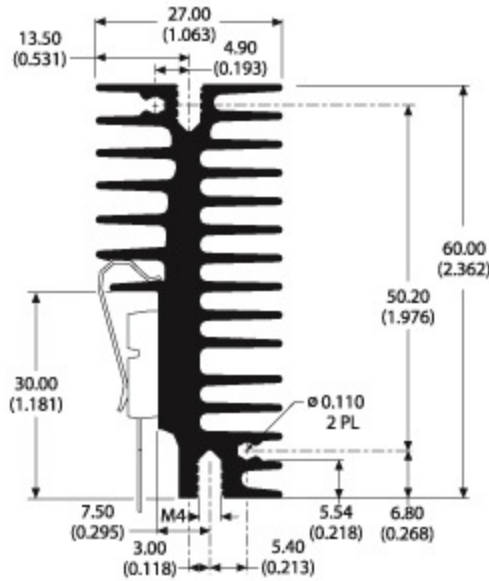

78245 3U05500G

Part Number 78245 is an aluminum Max Clip Extrusion that is 27 mm (1.06 in.) wide and 60 mm (1.06 in.) tall. Full Bar Length measuring 2499.4 mm (98.4 in. or 8.2 ft.)

- ☒ Buy Product
☐ Request a Quote

Cut type

Cut to length ▾

Cut length

5.5 ☒ in ☐ mm

Finish

Unfinished / Wash ▾

Quantity

− 1 +

\$800.00

\$800.00 Price per piece

Add to Cart

Product Details

Data and Performance

Application

Product Overview

Product Description

Extrusion UOM

RoHS

Bar Length (m)

Width (mm)

Width (in.)

Bar Length (mm)

Height (in.)

Height (mm)

Extrusion Type

Extrusion Class

Bar Length (ft.)

Material

Profile Width Range (mm)

Cooling Type

Full Part Number

Part Number Add Ons

Height Range (mm)

Part Number 78245 is an aluminum Max Clip Extrusion that is 27 mm (1.06 in.) wide and 60 mm (1.06 in.) tall. Full Bar Length measuring 2499.4 mm (98.4 in. or 8.2 ft.)

ft

Compliant

2.4994

27

1.06

2499.4

2.36

60

Max Clip Extrusion

A

8.2

6063 Aluminum

0-50mm

Passive Air, Active Air

782451F00000

1F00000

50-100mm

Support

Locations
Privacy Policy
Cookie Policy
Terms and Conditions
Return Policy
Regulatory and Compliance

About Aavid

Products
Manufacturing Capabilities
Design & Engineering Services
Boyd Corporate Website

Follow Us

Newsletter Sign Up



Site and all content © Aavid, Thermal Division of Boyd Corporation
eCommerce & Integrations powered by Clarity