 


Female connector – straight – 32 and 48 positions





 
 
 


 
 
 


PRODUCT DRAWING

DESCRIPTION

- Solder pin, wire wrap and solder lug
- Quality class 3 (also available in quality class 2 or 1)
- Special assembly on request

PRODUCT DRAWING

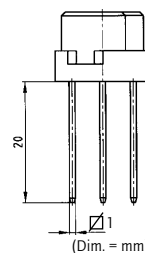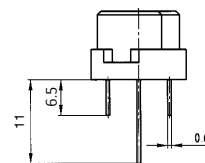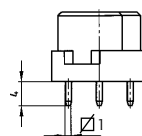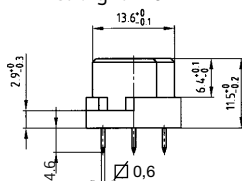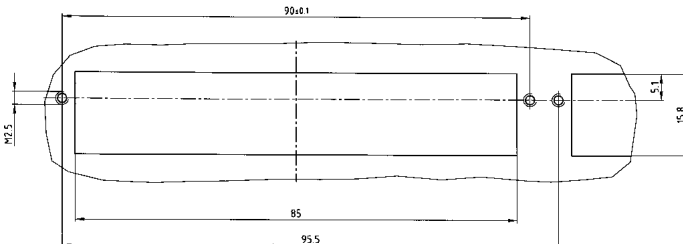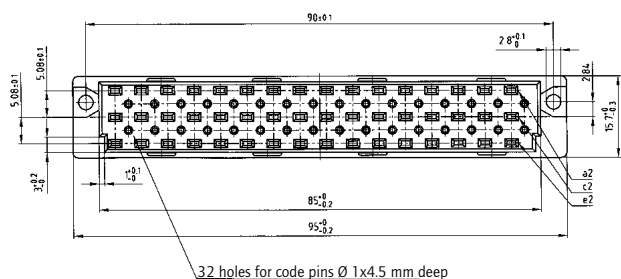

ORDER DATA

No. of Pos.	Row	• = contact, + = no contact				Solder pin straight 4.6 mm $\varnothing$ 0.6 mm	Solder pin straight 4.0 mm $\varnothing$ 1 mm	Solder lug	Wire Wrap
		Pos.	2	4	6				
32	a		•	•	•	122 A 13099 X	122 A 13129 X	122 A 13149 X	122 A 13169 X
	c		•	•	•				
	e	+	+	+	+				
32	a		•	•	•	122 A 13109 X	122 A 13139 X	122 A 13159 X	122 A 13179 X
	c	+	+	+	+				
	e	•	•	•	•				
48	a		•	•	•	122 A 13119 X	122 A 11619 X	122 A 11629 X	122 A 11609 X
	c	•	•	•	•				
	e	•	•	•	•				