



15 MM RIGHT ANGLE BASED LED



FEATURES / BENEFITS

Single and Double Sided

- ▲ Long life- up to 100,000 hours
- ▲ Energy savings- LEDs are eight times more efficient than incandescent bulbs
- ▲ Durability- vibration and shock resistant
- ▲ Non-polarized product operates at 10-12 volts AC/DC

SPECIFICATIONS


SINGLE SIDED

Part Number	Color	Vf	Watts	Intensity per Direction	Peak (nm) Wavelength
586-5611-202	Red	12 AC/DC	2	4	639
586-5613-202	Yellow	12 AC/DC	2	4	594
586-5615-202	Blue	12 AC/DC	1.5	3	465
586-5616-202	White	12 AC/DC	1.5	5.6	*
586-5617-202	Green	12 AC/DC	1.5	3.4	505
586-5621-202	Red	12 AC/DC	4	4	639
586-5632-202	Green	12 AC/DC	3	3.4	505
586-5633-202	Yellow	12 AC/DC	4	4	594
586-5635-202	Blue	12 AC/DC	3	3	465
586-5636-202	White	12 AC/DC	3	5.6	*

DOUBLE SIDED

* Typical Color Coordinates: X .291, Y .305

Dimensions in inches [mm]

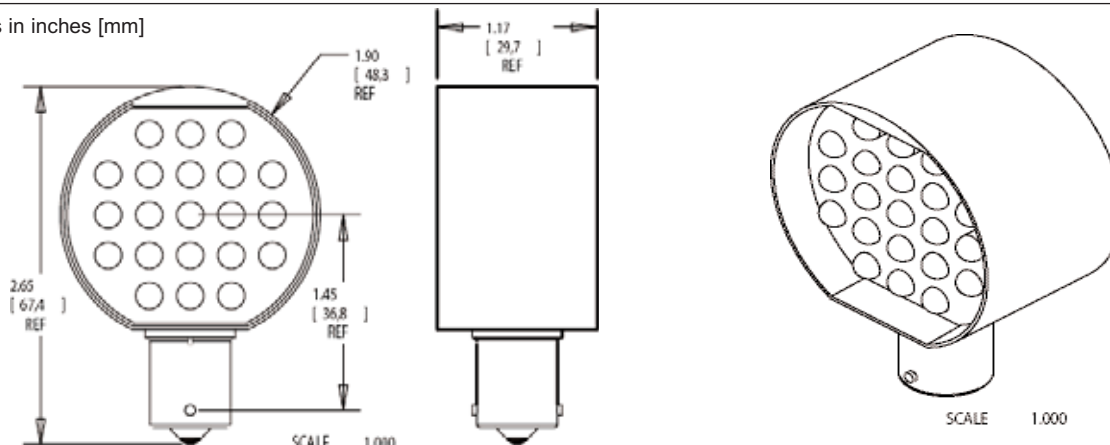

Dialight Corporation

1501 Route 34 South • Farmingdale, NJ 07727 USA

Tel: (1) 732-919-3119 • Fax: (1) 732-751-5778 • www.dialight.com

a Roxboro Group Company



MDTR586X001_B