

# Fuse Holders for ¼" x 1 ¼" and 5 x 20mm Fuses

## HTB Panel Mount Series



### Description

- For ¼" x 1 ¼" and 5 x 20mm fuses
- All holder bodies have the option of using ¼" x 1 ¼" or 5 x 20mm carriers
- Withstands 15 to 20 Lb-In torque to mounting nut when mounting fuse holder to panel
- High temperature, flame retardant, Thermoplastic meets UL 94V0



### Specifications

| Product Code | UL Rating (amps) | CSA Rating (amps) | Voltage Rating | Fuse Size | Quick Connect |
|--------------|------------------|-------------------|----------------|-----------|---------------|
| HTB-X2I      | 20               | 16                | 250            | ¼" x 1 ¼" | ¾"            |
| HTB-X4I      | 20               | 16                | 250            | ¼" x 1 ¼" | ¾"            |
| HTB-X6I      | 20               | 16                | 250            | ¼" x 1 ¼" | ¾"            |
| HTB-X8I      | 20               | 16                | 250            | ¼" x 1 ¼" | ¾"            |
| HTB-X2M      | 16               | 16                | 250            | 5 x 20mm  | ¾"            |
| HTB-X4M      | 16               | 16                | 250            | 5 x 20mm  | ¾"            |
| HTB-X6M      | 16               | 16                | 250            | 5 x 20mm  | ¾"            |
| HTB-X8M      | 16               | 16                | 250            | 5 x 20mm  | ¾"            |

 
 
### Agency Information

- UL Recognized: IZLT2, E14853
- CSA Component Acceptance: Class 6225-01, File 47235
- VDE Certified: 136128, HTB-XXM
- SEMKO Certification: Ref. #0146149/01, HTB-XXM
- CE


### Maximum Panel Thickness

| Body Type | Inch  | mm   |
|-----------|-------|------|
| HTB-2     | 0.30  | 7.62 |
| HTB-3     | 0.30  | 7.62 |
| HTB-4     | 0.125 | 3.18 |
| HTB-5     | 0.125 | 3.18 |
| HTB-6     | 0.30  | 7.62 |
| HTB-8     | 0.125 | 3.18 |
| HTB-9     | 0.125 | 3.18 |





### Replacement Parts



### Mounting Dimensions - in (mm)

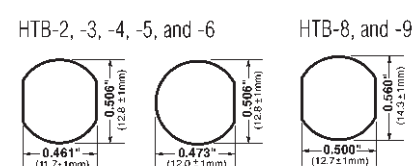

### Dimensions - in (mm)
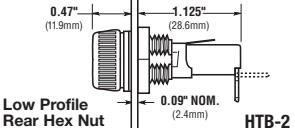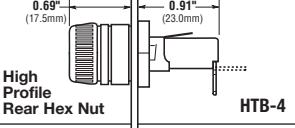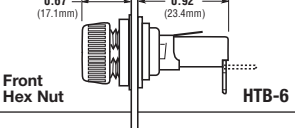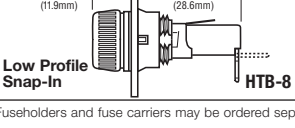
| Knob Type Carrier                                                                                                                    | Maximum Panel Thickness | Terminal Options                                                                                  |           |                                                                                                   |           | Carrier Options                                                                       |                                                                                       |
|--------------------------------------------------------------------------------------------------------------------------------------|-------------------------|---------------------------------------------------------------------------------------------------|-----------|---------------------------------------------------------------------------------------------------|-----------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
|                                                                                                                                      |                         | Solder/<br>¾" Quick-Connect                                                                       |           | ¾" Quick-Connect                                                                                  |           | Carrier Options                                                                       |                                                                                       |
|                                                                                                                                      |                         | In-Line                                                                                           | Rt. Angle | In-Line                                                                                           | Rt. Angle | ¼" x 1 ¼"<br>("I" Equals Inches)                                                      | 5 x 20mm<br>("M" Equals Metric)                                                       |
|                                                                                                                                      |                         |  0.34" (8.7mm) |           |  0.33" (8.3mm) |           |  |  |
|  <b>Low Profile Rear Hex Nut</b><br><b>HTB-2</b>  | 0.30"<br>7.62mm         | HTB-22I-R                                                                                         | HTB-24I-R | HTB-26I-R                                                                                         | HTB-28I-R | 3                                                                                     | —                                                                                     |
|                                                                                                                                      |                         | HTB-22M-R                                                                                         | HTB-24M-R | HTB-26M-R                                                                                         | HTB-28M-R | —                                                                                     | 3                                                                                     |
|  <b>High Profile Rear Hex Nut</b><br><b>HTB-4</b> | 0.125"<br>3.18mm        | HTB-42I-R                                                                                         | HTB-44I-R | HTB-46I-R                                                                                         | HTB-48I-R | 3                                                                                     | —                                                                                     |
|                                                                                                                                      |                         | HTB-42M-R                                                                                         | HTB-44M-R | HTB-46M-R                                                                                         | HTB-48M-R | —                                                                                     | 3                                                                                     |
|  <b>Front Hex Nut</b><br><b>HTB-6</b>             | 0.30"<br>7.62mm         | HTB-62I-R                                                                                         | HTB-64I-R | HTB-66I-R                                                                                         | HTB-68I-R | 3                                                                                     | —                                                                                     |
|                                                                                                                                      |                         | HTB-62M-R                                                                                         | HTB-64M-R | HTB-66M-R                                                                                         | HTB-68M-R | —                                                                                     | 3                                                                                     |
|  <b>Low Profile Snap-In</b><br><b>HTB-8</b>       | 0.125"<br>3.18mm        | HTB-82I-R                                                                                         | HTB-84I-R | HTB-86I-R                                                                                         | HTB-88I-R | 3                                                                                     | —                                                                                     |
|                                                                                                                                      |                         | HTB-82M-R                                                                                         | HTB-84M-R | HTB-86M-R                                                                                         | HTB-88M-R | —                                                                                     | 3                                                                                     |

Fuseholders and fuse carriers may be ordered separately.

## Dimensions - in (mm)

| Screwdriver Type Carrier                                                                           | Maximum Panel Thickness | Terminal Options               |                  |                    |                   | Carrier Options                    |                                 |
|----------------------------------------------------------------------------------------------------|-------------------------|--------------------------------|------------------|--------------------|-------------------|------------------------------------|---------------------------------|
|                                                                                                    |                         | Solder/<br>3/16" Quick-Connect |                  | 1/4" Quick-Connect |                   | 1/4" x 1/4"<br>("I" Equals Inches) | 5 x 20mm<br>("M" Equals Metric) |
|                                                                                                    |                         | In-Line                        | Rt. Angle        | In-Line            | Rt. Angle         | Screwdriver                        | Screwdriver                     |
|                                                                                                    |                         |                                |                  |                    |                   |                                    |                                 |
| Common Dimensional Data:<br>(Screwdriver Slotted)<br>1.75" (44.5mm)<br>NOTE: Plus In-Line Terminal | 0.30"<br>7.62mm         | 0.34"<br>(8.7mm)               | 0.33"<br>(8.3mm) | 0.47"<br>(11.9mm)  | 0.45"<br>(11.5mm) |                                    |                                 |
|                                                                                                    |                         | HTB-32I-R                      | HTB-34I-R        | HTB-36I-R          | HTB-38I-R         | 3                                  | —                               |
|                                                                                                    | 0.125"<br>3.18mm        | HTB-32M-R                      | HTB-34M-R        | HTB-36M-R          | HTB-38M-R         | —                                  | 3                               |
|                                                                                                    |                         | HTB-52I-R                      | HTB-54I-R        | HTB-56I-R          | HTB-58I-R         | 3                                  | —                               |
|                                                                                                    | 0.125"<br>3.18mm        | HTB-52M-R                      | HTB-54M-R        | HTB-56M-R          | HTB-58M-R         | —                                  | 3                               |
|                                                                                                    |                         | HTB-92I-R                      | HTB-94I-R        | HTB-96I-R          | HTB-98I-R         | 3                                  | —                               |
|                                                                                                    | 0.125"<br>3.18mm        | HTB-92M-R                      | HTB-94M-R        | HTB-96M-R          | HTB-98M-R         | —                                  | 3                               |
|                                                                                                    |                         |                                |                  |                    |                   |                                    |                                 |

Fuseholders and fuse carriers may be ordered separately.

## Ordering Information

|                                                                                                                                                                                                                                                                                      |  |                                                                                                                                                                                                                |  |                                                          |  |                                                                           |  |                                                                     |  |
|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--|----------------------------------------------------------|--|---------------------------------------------------------------------------|--|---------------------------------------------------------------------|--|
|                                                                                                                                                                                                                                                                                      |  |                                                                                                                                                                                                                |  |                                                          |  | <div>S</div> <div>P</div>                                                 |  | <b>FUSE CARRIER ONLY</b><br><br><div></div> <div></div> <div></div> |  |
| <b>Packing</b><br>(Blank) — Std.<br>BK/ — Bulk                                                                                                                                                                                                                                       |  | <b>Product Symbol</b>                                                                                                                                                                                          |  | <b>Fuse Carrier</b><br>I — 1/4" x 1 1/4"<br>M — 5 x 20mm |  | <b>Splash Proof</b><br>Cap with O-Ring<br>(Optional on Knob Holders Only) |  |                                                                     |  |
| <b>Body Configuration and Mounting Knob Holders</b><br>2 — Low Profile (Rear Panel Hex-Nut)<br>4 — High Profile<br>*6 — (Front Panel Hex-Nut)<br>8 — Low Profile (Snap-In)<br><b>Screwdriver Slotted Holders</b><br>3 — Low Profile<br>5 — High Profile<br>9 — Low Profile (Snap-In) |  | <b>Rear Terminal Configuration</b><br>2 — Solder / 3/16" Quick-Connect (In-Line)<br>4 — Solder / 3/16" Quick-Connect (Right Angle)<br>6 — 1/4" Quick-Connect (In-Line)<br>8 — 1/4" Quick-Connect (Right Angle) |  | <div>-R</div>                                            |  | <b>RoHS Compliant</b>                                                     |  |                                                                     |  |

\*Profile varies with panel thickness. Holder installs thru rear of panel.

| Packaging             |                                                        |
|-----------------------|--------------------------------------------------------|
| Packaging Code Prefix | Description                                            |
| Blank                 | 10 fuse holders packed into a carton                   |
| BK                    | 100 fuse holders packed into a cardboard shelf package |

The only controlled copy of this Data Sheet is the electronic read-only version located on the Cooper Bussmann Network Drive. All other copies of this document are by definition uncontrolled. This bulletin is intended to clearly present comprehensive product data and provide technical information that will help the end user with design applications. Cooper Bussmann reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Cooper Bussmann also reserves the right to change or update, without notice, any technical information contained in this bulletin. Once a product has been selected, it should be tested by the user in all possible applications.

Life Support Policy: Cooper Bussmann does not authorize the use of any of its products for use in life support devices or systems without the express written approval of an officer of the Company. Life support systems are devices which support or sustain life, and whose failure to perform, when properly used in accordance with instructions for use provided in the labeling, can be reasonably expected to result in significant injury to the user.

© 2009 Cooper Bussmann  
St. Louis, MO 63178  
www.cooperbussmann.com



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Cooper Bussmann:

[STI](#) [BK/FTI](#) [BK/FTM](#) [STM](#) [ST-COVER](#) [BK/STM](#) [FT-3](#)

## Eaton:

[BK/FTI-SP](#) [FTI](#)