


SPDT

- Raised and Recessed Rocker, and Toggle Actuated Styles
- SPDT with a Common Pole, or SPDT with 2 Isolated Circuits
- Spring and Ball Contact
- Top Tape Seal Option for Most Styles
- RoHS Compliant

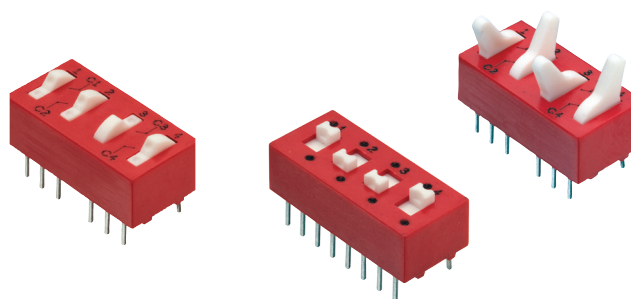

Series 76 Raised Rocker

Top View Dimensions:

- Overall Width: $.380 \pm .010$ (9,65 $\pm$ 0,25)
- Pin Spacing: $.380 \pm .010$ (9,65 $\pm$ 0,25)
- Pin Diameter: $.020 + .005 - .000$ (0,51 + 0,13)
- Pin Length: $.050 \pm .005$ (1,27 $\pm$ 0,13)
- Pin Spacing (Center-to-Center): $.090 \pm .005$ (2,29 $\pm$ 0,13) TYP.
- Pin Spacing (Edge-to-Edge): $.100 \pm .005$ (2,54 $\pm$ 0,13) TYP.
- Pin Diameter (Alternative): $.012 \pm .001$ (0,30 $\pm$ 0,03)
- Pin Length (Alternative): $.300 + .030 - .000$ (7,62 + 0,76)

Side View Dimensions:

- Overall Height: $.295 + .000 - .000$ (7,49 - 0,51)
- Pin Height: $.156 + .015 - .010$ (3,96 + 0,38 - 0,25)

Toggle-DIP

Top View Dimensions:

- Overall Width: $.447 \pm .015$ (11,35 $\pm$ 0,38)
- Pin Spacing: $.380 \pm .010$ (9,65 $\pm$ 0,25)
- Pin Diameter: $.020 + .005 - .000$ (0,51 + 0,13)
- Pin Length: $.050 \pm .005$ (1,27 $\pm$ 0,13)
- Pin Spacing (Center-to-Center): $.090 \pm .005$ (2,29 $\pm$ 0,13) TYP.
- Pin Spacing (Edge-to-Edge): $.100 \pm .005$ (2,54 $\pm$ 0,13) TYP.
- Pin Diameter (Alternative): $.012 \pm .001$ (0,30 $\pm$ 0,03)
- Pin Length (Alternative): $.300 + .030 - .000$ (7,62 + 0,76)

Side View Dimensions:

- Overall Height: $.295 + .000 - .000$ (7,49 - 0,51)
- Pin Height: $.156 + .015 - .010$ (3,96 + 0,38 - 0,25)


Recessed Rocker

Top View Dimensions:

- Overall Width: $.447 \pm .015$ (11,35 $\pm$ 0,38)
- Pin Spacing: $.380 \pm .010$ (9,65 $\pm$ 0,25)
- Pin Diameter: $.020 + .005 - .000$ (0,51 + 0,13)
- Pin Length: $.050 \pm .005$ (1,27 $\pm$ 0,13)
- Pin Spacing (Center-to-Center): $.090 \pm .005$ (2,29 $\pm$ 0,13) TYP.
- Pin Spacing (Edge-to-Edge): $.100 \pm .005$ (2,54 $\pm$ 0,13) TYP.
- Pin Diameter (Alternative): $.012 \pm .001$ (0,30 $\pm$ 0,03)
- Pin Length (Alternative): $.300 + .030 - .000$ (7,62 + 0,76)

Side View Dimensions:

- Overall Height: $.295 + .000 - .000$ (7,49 - 0,51)
- Pin Height: $.156 + .015 - .010$ (3,96 + 0,38 - 0,25)

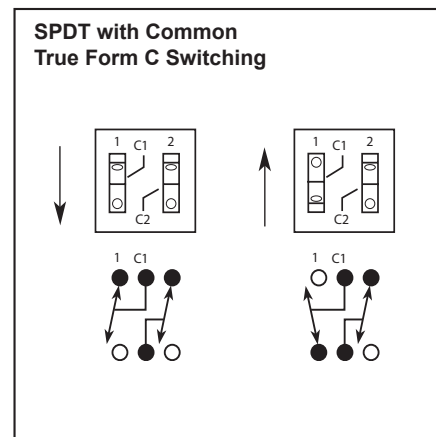


Series 78 Slide

Top View Dimensions:

- Overall Width: $0.380 \pm .005$ (9,65 $\pm$ 0,13)
- Pin Spacing (Pitch): $0.100 \pm .002$ (2,54 $\pm$ 0,05)
- Pin Diameter: $.020 \pm .002$ (0,51 $\pm$ 0,05)
- Pin Position (Typical): $.090 \pm .005$ (2,29 $\pm$ 0,13) TYP.
- Pin Position (Typical): $.100 \pm .005$ (2,54 $\pm$ 0,13) TYP.
- Dimension A: SEE CHART

Side View Dimensions:

- Top Surface Width: $.070$ (1,78) REF.
- Top Surface Height: $.295 \pm .000 - .020$ (7,49 $\pm$ 0 - 0,51)
- Pin Height: $.156 \pm .015 - .010$ (3,96 $\pm$ 0,38 - 0,25) TYP.
- Pin Position (Typical): $A = .245 \pm .000 - .020$ (6,22 $\pm$ 0 - 0,51)
- Pin Position (Typical): $.180 \pm .010$ (4,57 $\pm$ 0,25)
- Pin Position (Typical): $.012 \pm .001$ (0,30 $\pm$ 0,03)
- Pin Position (Typical): $.300 \pm .030 - .000$ (7,62 $\pm$ 0,76 - 0)

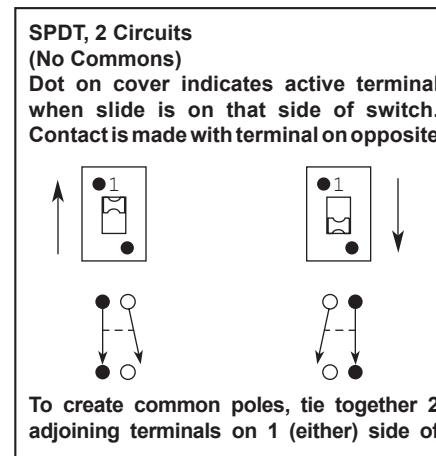

Circuitry	Positions	Length Inches	Length Metric	No./ Tube	Raised Type*	Recessed Rockers*	Toggle-DIP*
SPDT Form C	2 4	0.380" 0.780"	9,7mm 19,8mm	27 13	76SC02T 76SC04T	76RSC02T 76RSC04T	76STC02T 76STC04T
SPDT 2 Circuits	1 2 3 4 5	0.280" 0.480" 0.680" 0.880" 1.080"	7,1mm 12,2mm 17,3mm 22,4mm 27,4mm	35 21 15 12 9	78J01T 78J02T 78J03T 78J04T 78J05T	— — — — —	— — — — —

**Available from your local
Grayhill Distributor.
For prices and discounts, contact a local
Sales Office, an authorized local Distributor
or Grayhill.**

Grayhill, Inc. • 561 Hillgrove Avenue • LaGrange, Illinois 60525-5997 • USA • Phone: 708-354-1040 • Fax: 708-354-2820 • www.grayhill.com