

Number of contacts


20–68



Male and female connectors, angled


Identification	No. of contacts	Part No.	
Male and female connectors with angled solder pins		Male connector	Female connector
	20		60 11 020 51 ..
	26		60 11 026 51 ..
	28	60 11 028 5232	
	36	60 11 036 5232	60 11 036 51 ..
	50	60 11 050 5232	60 11 050 51 ..
	68	60 11 068 5232	60 11 068 51 ..
Without board lock	32		
With board lock	40		

Dimensions for male connectors


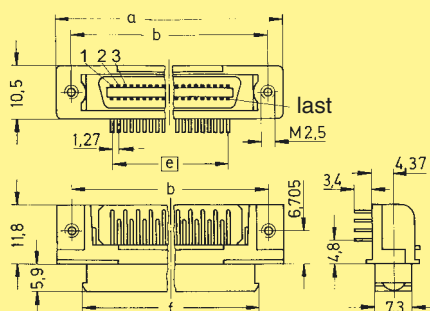


	a	b _{±0.1}	c	e	f	g	h
20	33.40	27.40	16.45	9 x 1.27 = 11.43	23.30	23.70	27.45
26	37.16	31.26	20.26	12 x 1.27 = 15.24	27.11	27.50	31.25
28	38.48	32.48	—	13 x 1.27 = 16.51	28.38	28.80	32.50
36	43.56	37.56	26.61	17 x 1.27 = 21.59	33.46	33.90	37.60
50	52.45	46.45	35.50	24 x 1.27 = 30.48	42.35	42.80	46.50
68	63.88	57.88	46.93	33 x 1.27 = 41.91	53.78	54.20	57.90


Board drillings

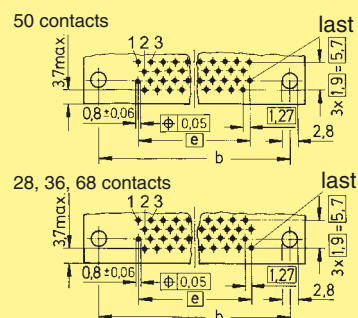

Dimensions for female connectors

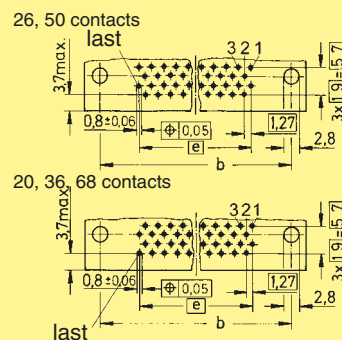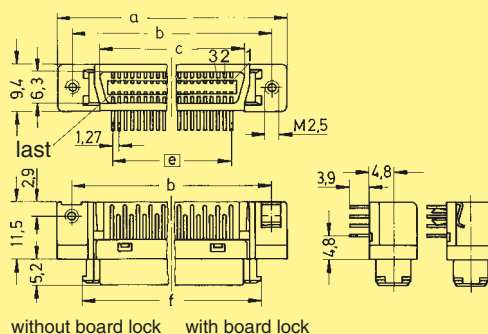

Panel cut out

 

Dimensions in mm