



Wire Nuts

159-1803, 159-1804, 159-2214, 159-2216

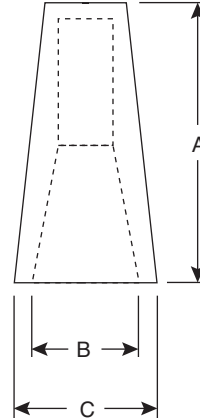

Wire Nuts

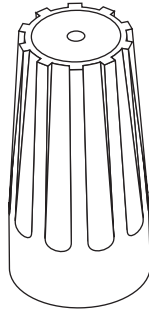

SPECIFICATIONS

| | |
|---------------------|------------|
| Temperature Rating: | 105°C |
| Electrical Rating: | 300V |
| Retaining Spring: | Steel Wire |

| MOUSER STOCK NO. | Color Coding | AWG Combination | | Dimensions: In. | | |
|------------------|--------------|-----------------|-------------|-----------------|------|------|
| | | Min. | Max. | A | B | C |
| 159-2214 | Orange | #20x3 | #16x3 | .693 | .291 | .386 |
| 159-2216 | Gray | #20x1+#22x1 | #16x2 | .598 | .264 | .339 |
| 159-1803 | Yellow | #20x3 | #16x3+#18x1 | .866 | .39 | .50 |
| 159-1804 | Red | #14x1+#18x1 | #14x4+#18x1 | .965 | .433 | .551 |

Date Last Revised: 01-15-19

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300722

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

159-1803, 159-1804, 159-2214, 159-2216