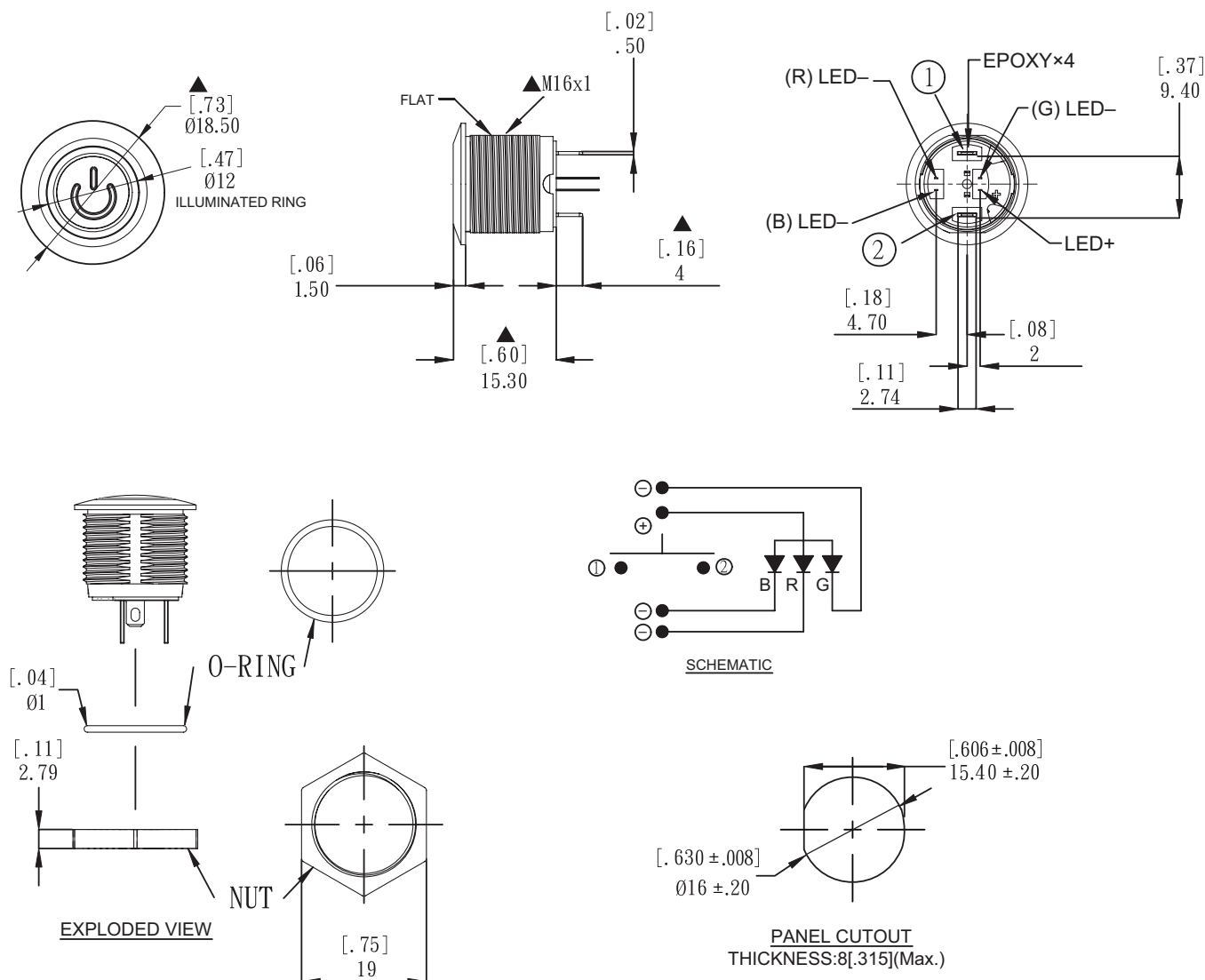


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 2A/36VDC.
- Life: 200,000 Make-And-Break Cycles At Full Load.
- Insulation Resistance: 1,000MΩ Min. at 500VDC
- Dielectric Strength: 2,000V RMS@ sea level.
- Contact Resistance: 50mΩ Max. @1A/12VDC(Initial Value)

Mechanical Specifications:

- Life: 1,000,000 Cycles.
- Operating Temperature: -20°C~+70°C

Note:

- RoHS Compliant by Exemption

Illuminated Pushbutton Switch
108-163P0-EVX

**Mountain
Switch**

Available from Mouser Electronics

www.mouser.com

1-800-346-6873

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.