

LF5WA



LF81WA




Part No.	Emitting Color + Material	λ D (nm)	Lens Type	Iv (mcd) @20mA		Viewing Angle	Dimension
				Min.	Typ.		

LF5WAEMBGMBW	GaAsP/GaP	625	water clear	20	50	30°	T-1 3/4 (5mm) Round 1 ANODE RED 2 ANODE BLUE 5 COMMON CATHODE 3 ANODE GREEN 4 ANODE BLUE 6 COMMON CATHODE
	GaN	455		20	40		
	GaP	568		12	30		
	GaN	455		20	40		
LF5WAEMBGMBW	GaAsP/GaP	625	white diffused	12	30	60°	
	GaN	455		12	20		
	GaP	568		12	25		
	GaN	455		12	20		

LF81WAEMBGMBW	GaAsP/GaP	625	water clear	12	40	30°	10mm Round 1 ANODE RED 5 COMMON CATHODE 2 ANODE BLUE 4 ANODE BLUE 6 COMMON CATHODE 3 ANODE GREEN
	GaN	455		12	30		
	GaP	568		12	45		
	GaN	455		12	30		

VALUE ADDED LED LAMPS

LED lamp with forming/wire leads available

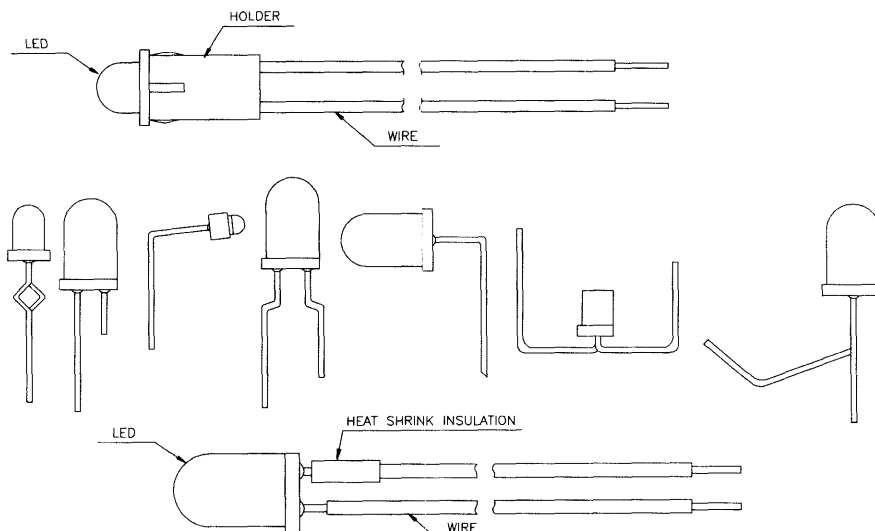

NOTES :

1. All dimensions are in millimeters (inches)
2. Tolerance is $\pm 0.25\text{mm}$ (0.01") unless otherwise noted.