


In-Line Stereo Jack

161-3300N-EX

KOBICONN

In-Line Stereo Jack

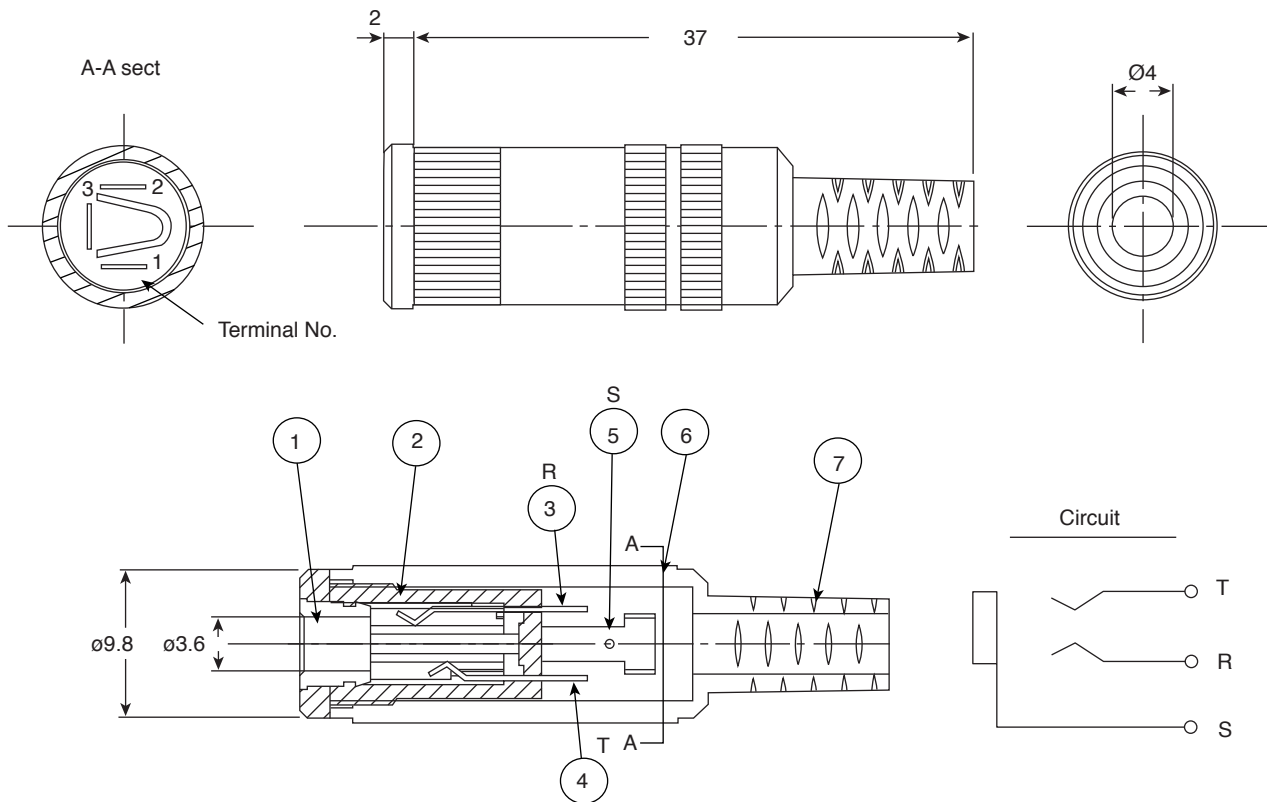

DIMENSIONS: mm

SPECIFICATIONS	
Dielectric Strength:	500V AC for 1 Min.
Contact Resistance:	50MΩ Max.
Insulation Resistance:	100MΩ Min. at 500V DC
RoHS Compliant by Exemption	

7	Cable Protector	PVC	1	Ni
6	Cap	BSBM	1	Ni
5	Contact C	BSR t=0.3	1	Ni
4	Contact B	PBS t=0.25	1	Ni
3	Contact A	PBS t=0.25	1	Ni
2	Housing	PA	1	
1	Sleeve	BSBM	1	Ni
	Part Name	Material	QTY	Finish

Date Last Revised: 02-27-17

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301446

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.