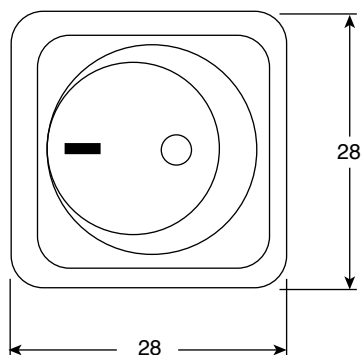
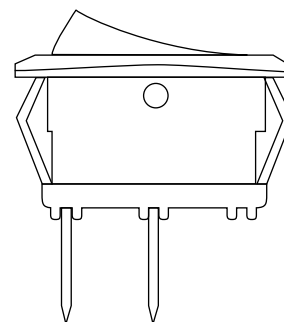
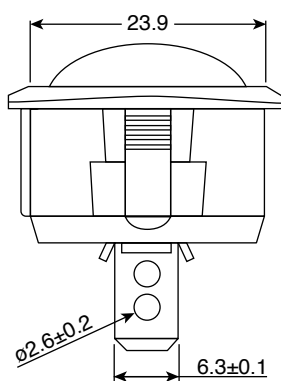
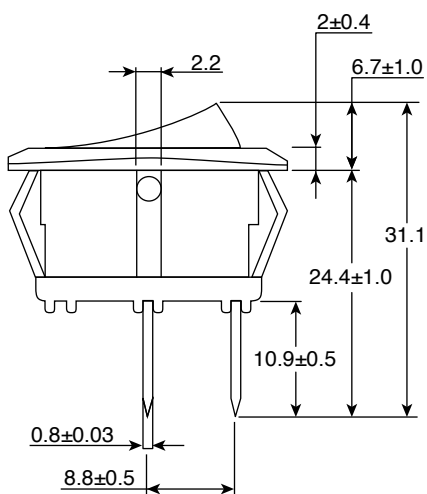


**DIMENSIONS: mm**

| Mounting Hole | Circuit Diagram |
|---------------|-----------------|
|               |                 |

**Mechanical Specifications:**

- Operating Temperature: -20-65 °C
- Switch Function: 2P SPST ON-OFF

**Material:**

- Frame: Nylon 66, Black
- Accentuator: Black, PC
- Printed: White, Hot Stamping

**Electrical Specifications:**

- Rating: 25A / 12V DC
- Contact Resistance: 50m Ω Max.
- Insulation Resistance: 500V DC 100M Ω Min.
- Dielectric Strength: 1500V AC 1 Minute

**Note:**

- RoHS Compliant
- Tolerances ±0.3 Unless Otherwise Specified

**Rocker Switch**  
103-R13-203A-EV

**Mountain**  
**Switch**