




PANEL PLUG RECEPTACLES

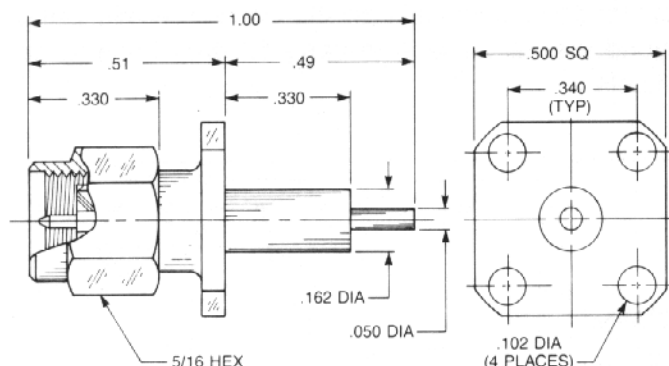

Straight Panel Plug Receptacle

- Extended contact and insulator
- 1/2" square flange

Captive contact:


9009-1113-000 (Gold plated)

9009-9113-000 (Passivated)

Noncaptive contact:

9009-1213-000 (Gold plated)

9009-9213-000 (Passivated)

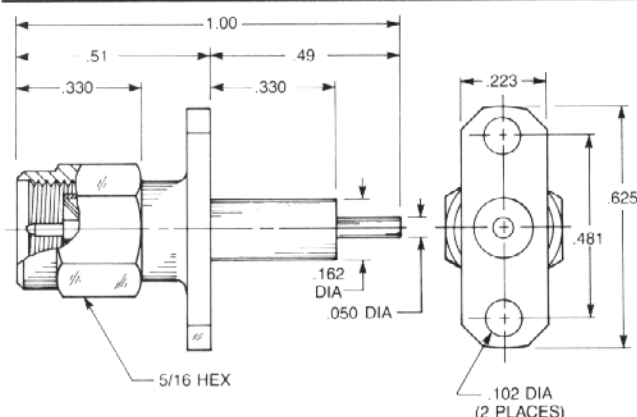

Straight Panel Plug Receptacle

- Extended contact and insulator
- 2-hole flange

Captive contact:


9055-1113-000 (Gold plated)

9055-9113-000 (Passivated)

Noncaptive contact:

9055-1213-000 (Gold plated)

9055-9213-000 (Passivated)

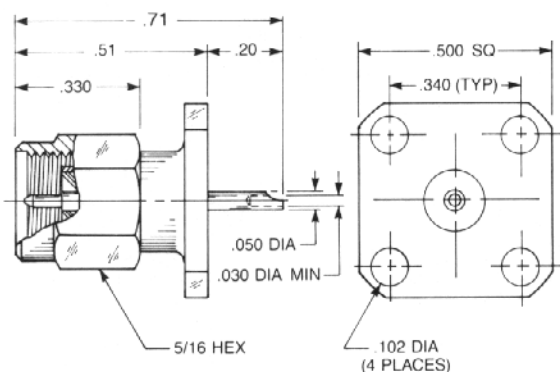


Straight Panel Plug Receptacle

- Solder pot contact
- 1/2" square flange

Captive contact:

9409-1113-000 (Gold plated)

9409-9113-000 (Passivated)

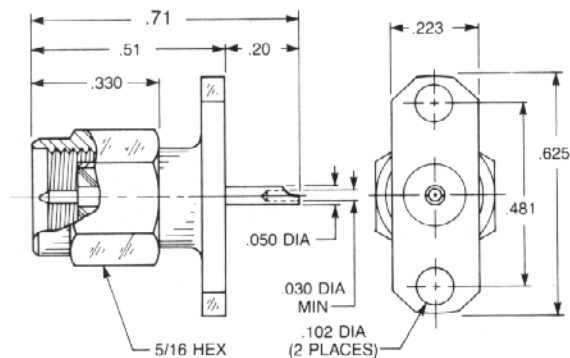

Straight Panel Plug Receptacle

- Solder pot contact
- 2-hole flange

Captive contact:

9455-1113-000 (Gold plated)

9455-9113-000 (Passivated)

Available with other contact and insulator configurations

e-mail: aepsales@aepconnectors.com

AEP New Haven, CT
203/776-2813

Straight Panel Plug Receptacle

- Tab contact
- 1/2" square flange

Captive contact:


9109-1113-000 (Gold plated)

9109-9113-000 (Passivated)

Noncaptive contact:

9109-1213-000 (Gold plated)

9109-9213-000 (Passivated)

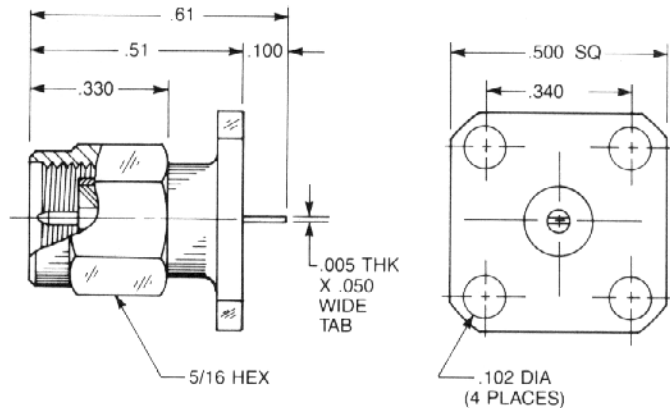

Straight Panel Plug Receptacle

- Tab contact
- 2-hole flange

Captive contact:


9155-1113-000 (Gold plated)

9155-9113-000 (Passivated)

Noncaptive contact:

9155-1213-000 (Gold plated)

9155-9213-000 (Passivated)

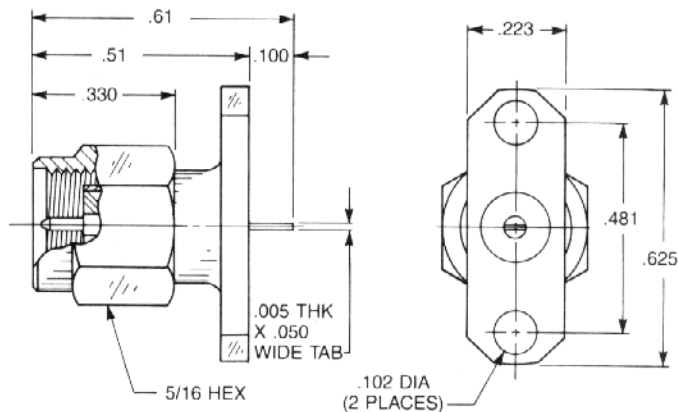


Right Angle Panel Plug Receptacle

- Solder pot contact
- 1/2" square flange

9454-1513-000 (Gold plated)

9454-9513-000 (Passivated)

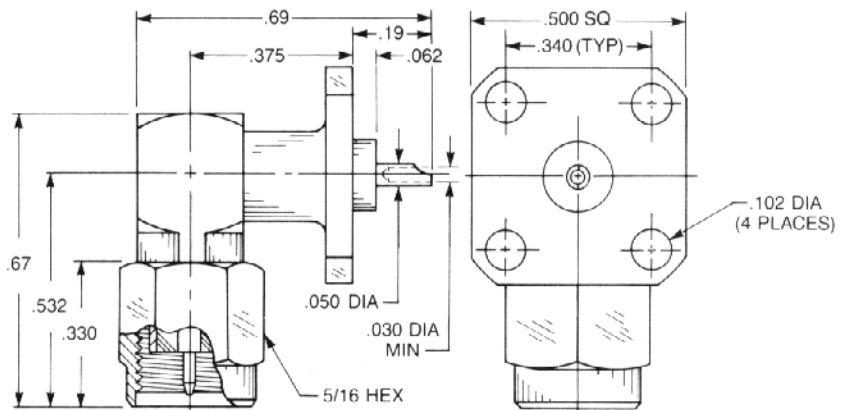

Right Angle Panel Plug Receptacle

- Tab contact
- 1/2" square flange

9154-1513-000 (Gold plated)

9154-9513-000 (Passivated)

