

STRAIGHT JACKS CRIMP TYPE FOR FLEXIBLE CABLES

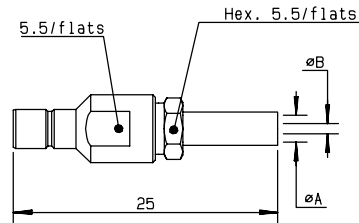


Fig. 1

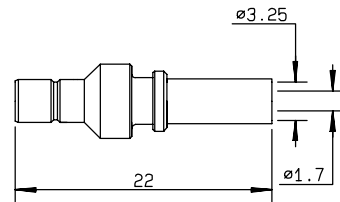


Fig. 2


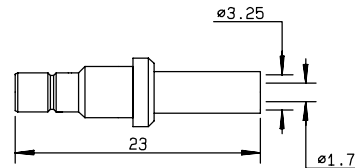


Fig. 3

cable	part number	fig.	dimensions		captive center contact	assembly	finish	note
			A	B				
2/50/S	R114 237 000	1	2.55	0.95	yes	M03	Gold	
2.6/50+75/S	R114 238 000	2			yes	M10	Gold	full crimp
2.6/50+75/S	R114 238 120	2			yes	M10	Nickel	full crimp
2.6/50+75/S	R114 239 000	1	3.25	1.7	yes	M03	Gold	
2.6/50/D	R114 245 020●	3			yes	M10	Nickel	full crimp

STRAIGHT JACKS CLAMP TYPE FOR FLEXIBLE CABLES

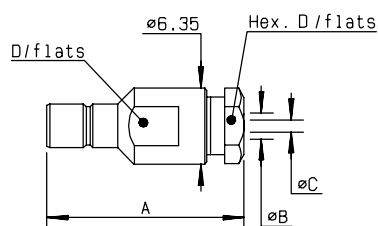

cable	part number	dimensions				captive center contact	assembly	finish	note
		A	B	C	D				
2/50/S	R114 203 000	21	2.2	1	5	yes	M02	Gold	
2/50/S	R114 203 133*●	16.5	2.2	1	5.5	yes	M01	Gold	conical braid clamp
2.6/50+75/S	R114 205 000	21	3	1.7	5	yes	M02	Gold	
2.6/50+75/S	R114 205 133	16.5	3	1.7	5.5	yes	M01	Gold	conical braid clamp

● upon request

* packaging: unit