




CALL NOW:
203 888-2133



Home > 6mm Hex Male-Female Standoffs

6MM HEX MALE-FEMALE STANDOFFS

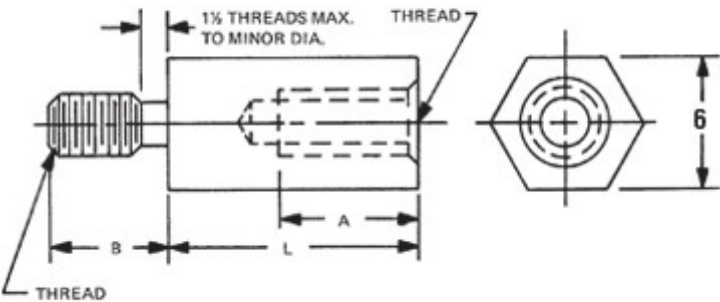

MINIMUM THREAD DEPTH "A"											
Thread	Body Length "L"										
	5	6	7	8	9	10	11	12	13	14	15
M2.5x0.45	1.9	2.9	3.9								
M3x0.5	1.8	2.8	3.8	4.8	5.8						
M3.5x0.6		2.5	3.5	4.5	5.5	6.5	7.5	8.5	9.5		
M4x0.7		2.1	3.1	4.1	5.1	6.1	7.1	8.1	9.1	10.1	11.1
In short lengths, "A" will be tapped to maximum depth. For non-standard parts, contact us .											

Qty1 *

Qty2

Qty3

Length *

Select	Part No.	Length
☒	M2140	5
☐	M2141	6
☐	M2142	7
☐	M2143	8

Home Previous Next
Related ASE

xxxxx
|
Length

xxxx
|
Thread

xx
|
Material

x
|
Finish

PART: M2140 3005 B 12

Red ?'s show missing selections. [Help](#)

[Material Specifications](#)
[Ordering non-standard items](#)
[Download a Drawing](#)

Add to Cart

6mm Hex Male-Female Standoffs

Select	Part No.	Length
☐	M2144	9
☐	M2145	10
☐	M2146	11
☐	M2147	12
☐	M2148	13
☐	M2149	14

Thread *

Select	Code	Thread	A	B
☐	2545	M2.5x0.45	4.8	3.97
☒	3005	M3x0.5	6.4	4.76
☐	3506	M3.5x0.6	9.5	6.35
☐	4007	M4x0.7	11.1	9.53

Material *

Select	Code	Material	RoHS
☐	AL	Aluminum	YES
☒	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Select	Finish
☒	12-Zinc
☐	13-Bright dip - brass
☐	14-Bright tin/copper flash
☐	15-Hot tin dip*
☐	16-Electro tin
☐	19-Caustic etch
☐	20-Passivation
☐	21-Dark grey anodize
☐	22-Clear anodize
☐	23-Yellow green anodize
☐	24-Black anodize
☐	25-Black oxide brass
☐	26-Black oxide SS