



(0,80mm) .0315"

VHDCR, VHDCP SERIES

VHDCI CONNECTORS

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?VHDCR or www.samtec.com?VHDCP

RoHS Compliant:

Yes


Lead-Free Solderable:

No

VHDCR Mates with:
VHDCP and Industry
Standard VHDCI
Cable Assemblies

VHDCP Mates with:
VHDCR

APPLICATION

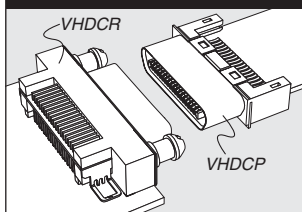Through-hole or
Edge MountRight Angle or
Edge Mount

36, 50 or 68 Positions

TYPE

NO. OF
POSITIONS

01

PLATING

MOUNTING
OPTION


VHDCR
= Right Angle
VHDCP
= Edge Mount

-36, -50, -68



-M
= 15μ" (0,38μm) Gold

-RA
= Right Angle
(Required for VHDCR)
-EM
= Edge Mount
(Required for VHDCP)


NO. OF POSITIONS	A VHDCR	B VHDCP
36	(29,90) 1.177	(21,80) .858
50	(35,50) 1.400	(27,40) 1.079
68	(42,70) 1.681	(34,60) 1.362

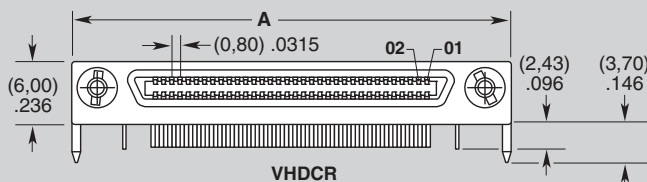

VHDCR

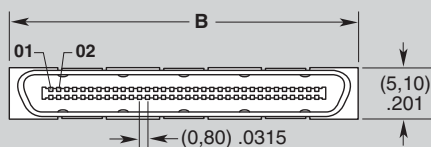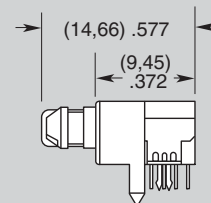

VHDCP

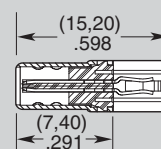

Note:
This Series is non-standard,
non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683