
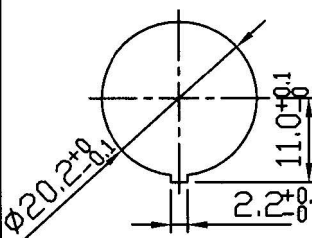
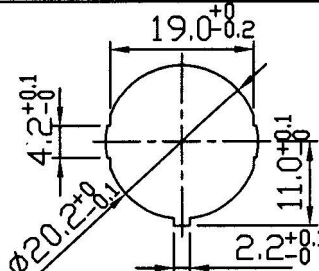


Rating	20A 12VDC		Mounting Hole	
Contact Resistance	50m ohm Max.			
Insulation Resistance	DC 500V 100M ohm Min.			
Dielectric Strength	AC 1500V 1 minute			
Operation Temperature	-25°~85°			
Switch Function	SPST ON-OFF (2 LEDs)			



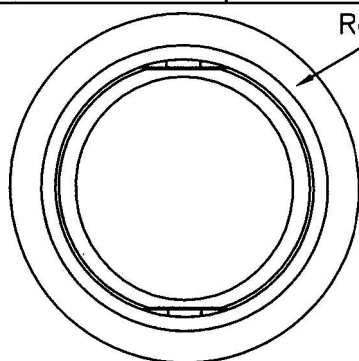


 
Round rocker switch with LED light ring.

Material:

Frame: Clear PC, blue
 Actuator: Nylon 6/6, black
 Bottom: Nylon 6/6, black
 Wire ass'y: 12V

Circuit Diagram

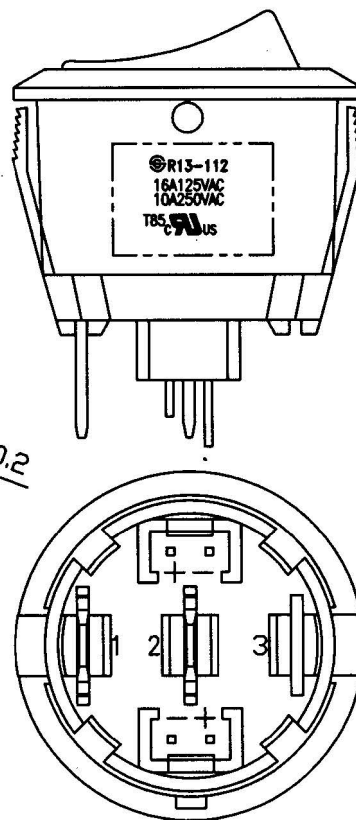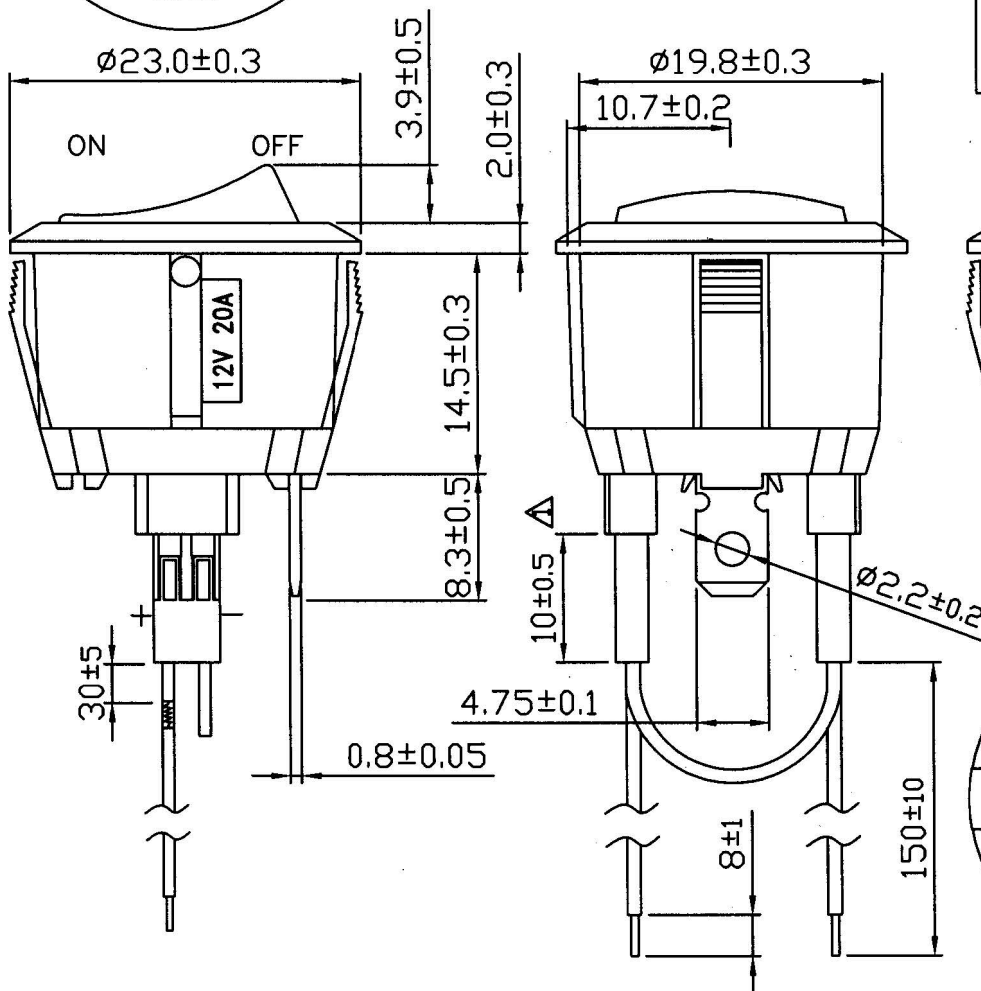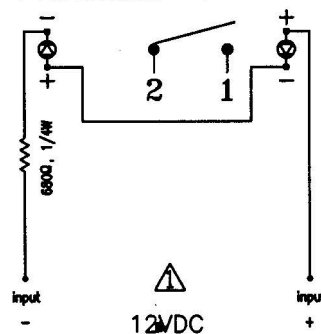

Date	Name	Description					△ NO
Drawn	Checked	Approved			Model Name	ROCKER SWITCH	
曹盈芳	研發部 96.9.28		Customer No.	112-R13-112AH-W1	Model No.	R13-112AHW1-02-UB	REV.
09/28/'07	鄭建誠	10/16	Unit	mm	SHIN CHIN INDUSTRIAL CO., LTD.		1