 
 

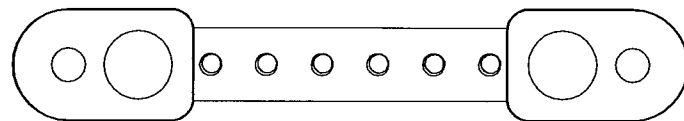
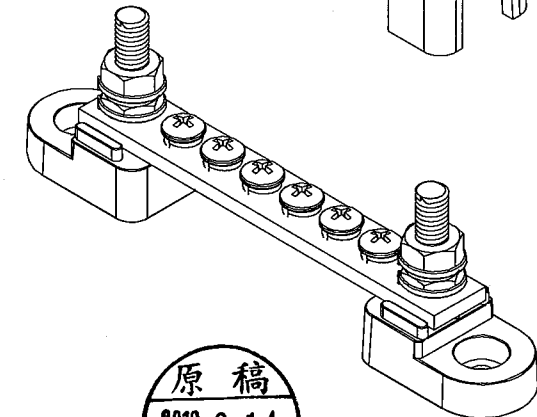
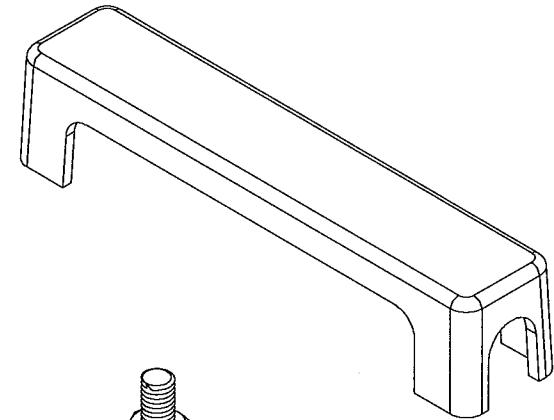
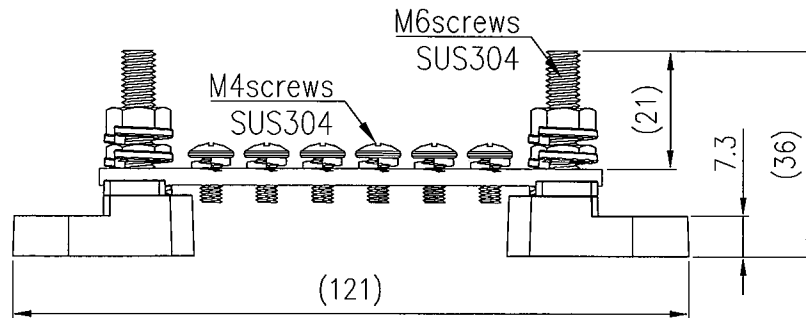


Voltage Rating	300 Volts AC Max & 48 Volts DC Max.		
current rated	M4 threaded studs (100A max.)		
Withstanding Voltage	1.6KV/2KV		
Contact resistance	20m ohm		
Operating temperature	-25 °C to +85 °C		

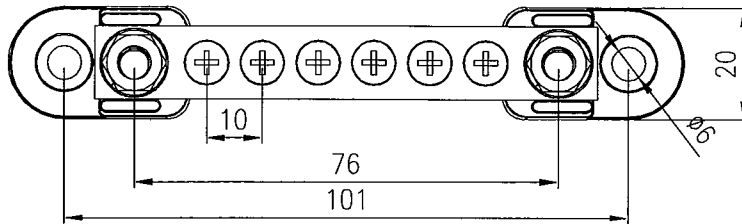

Specifications:

- * Bus material: Tin plated brass
- * Screw Material: Stainless Steel
- * Base material: Flame retardant plastic

Covers:

- * Flame-resistant flexible plastic Black recessed mounting

NOTE:

Tolerance ± 0.5 except noticed

				Drawn	Checked	Approved	SCI BOM No.	1690157	Model Name	Multi-Purpose Busbars (6P)	
				Rock Hsu			Customer No.		Model No.	R2-47-07-106	Rev.
Date	Name	Description	No.	5/30/18		5/31/18	Unit	mm	Shin Chin Industrial Co., Ltd.		0