

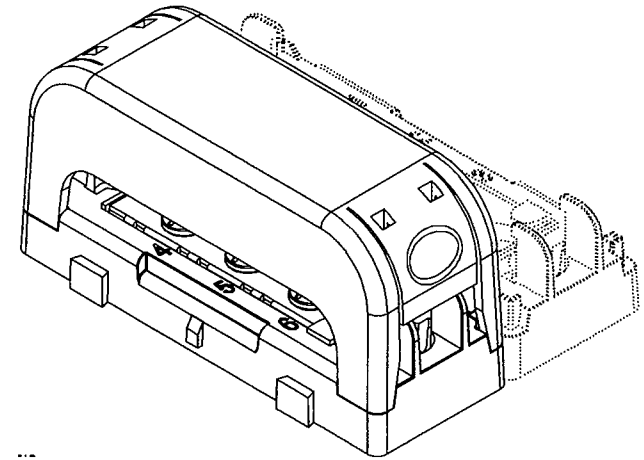
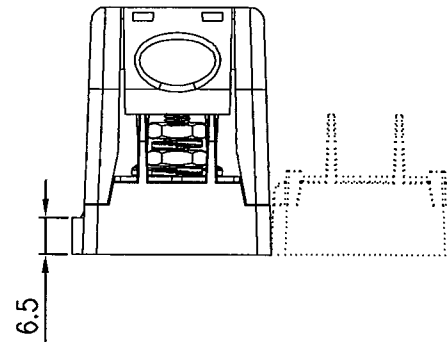
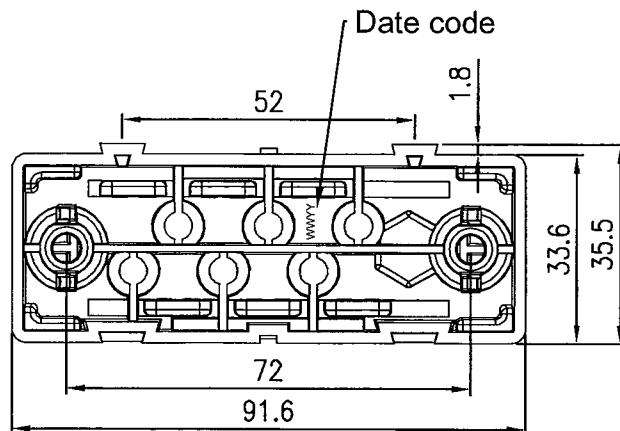


Voltage (Max.)	32 VDC.	Mounting Holes	Terminal Dim.
Input Terminal Rating	M5 threaded studs (100A max.)		
Connection Pad Option Available	Input wire size : #4-6 AWG.		
	Output wire size : #12-16 AWG.		
Torque Rating	20 in-lb (2.25Nm) max.		
Mounting Torque Rating	8 in-lb (0.9Nm) max.		
Operating temperature	-25 °C to +85 °C		

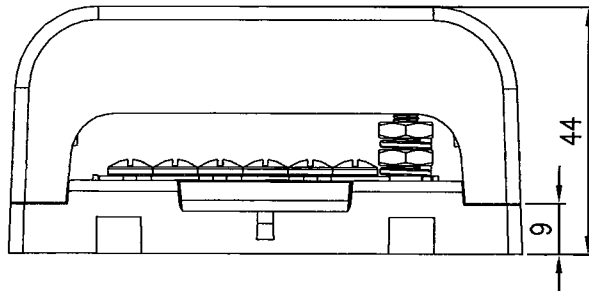

Parts Kit

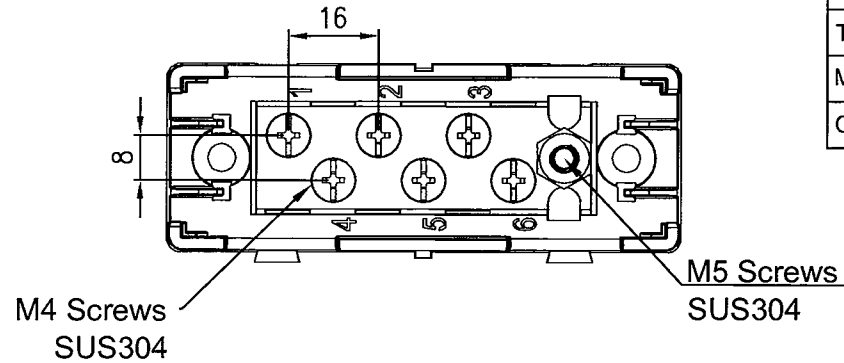

Sticker*1

Specifications:

- * Cover : PC.
- * Base : PBT. (Black)
- * Bus material: Tin plated brass
- * Screw Material: Stainless Steel

NOTE:

Tolerance ± 0.5 except noticed

				Drawn	Checked	Approved	SCI BOM No.	1690163		Model Name	Multi-Purpose Busbars (6P)	
			△	洪啟峰	洪啟峰	洪啟峰	Customer No.			Model No.	R2-49-07-106	Rev.
Date	Name	Description	No.	12/18/19	12/18/19	12/18/19	Unit	mm	Shin Chin Industrial Co., Ltd.			0