




Wire And Cable > Hook Up Wire

# 22759/43-16-9

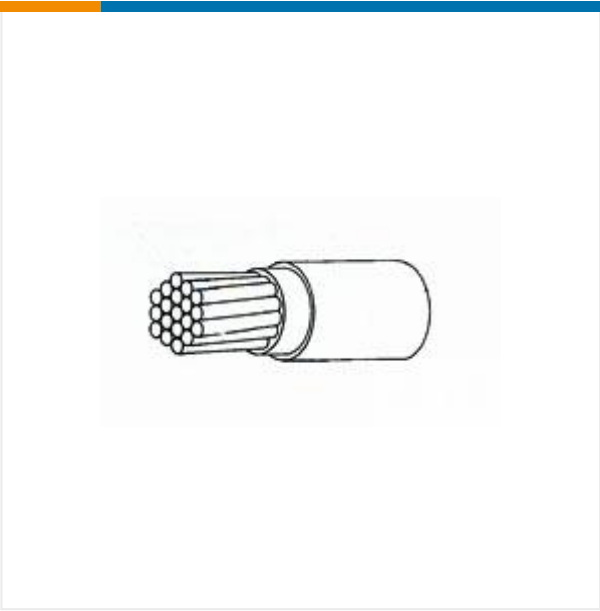

✓ ACTIVE

Raychem | CGS SP

TE Part # **22759/43-16-9**  
TE Internal #: **732994-001**  
Mil-Spec: **M22759/43-16-9**  
Alias #: **4-1195725-8**

Cable Type : **Spec 55A**  
Voltage Rating (V): **600**  
Wire Size (AWG): **16**  
Wire Size (mm²): **1.31**  
Operating Temperature Range (°C): **-65 – 200**

⌵ Add to List | Similar Products

Compatible Parts & Tooling

We are here to help!  
Get in touch with our product experts.

💬

CHAT WITH US

✉

EMAIL US

☎

CALL US

Feedback



|                                                                                                                                                                         |                                                                                                                                                                                                                                                                                                |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Please review product documents or <a href="#">contact us</a> for the latest agency approval information. Please Note: Use the Product Drawing for all design activity. |                                                                                                                                                                                                                                                                                                |
| Product Type Features                                                                                                                                                   | Cable Type : <b>Spec 55A</b><br>Cable Style : <b>Primary</b><br>Product Classification :<br><b>Cable - High Performance - Spec 44, 55 &amp; RCW</b><br>Product Type : <b>Wire</b>                                                                                                              |
| Configuration Features                                                                                                                                                  | Number of Strands : <b>19</b><br>Number of Conductors : <b>1</b>                                                                                                                                                                                                                               |
| Electrical Characteristics                                                                                                                                              | Voltage Rating (V): <b>600</b>                                                                                                                                                                                                                                                                 |
| Body Features                                                                                                                                                           | Wire Color : <b>White</b>                                                                                                                                                                                                                                                                      |
| Dimensions                                                                                                                                                              | Strand Size (AWG): <b>29</b><br>Wire Size (AWG): <b>16</b><br>Wire Size (mm²): <b>1.31</b><br>Conductor Diameter : <b>1.35 mm [ .053 in ]</b><br>Overall Outside Diameter : <b>1.96 mm [ .077 in ]</b><br>Insulation Thickness (in): <b>.009</b><br>Wire Diameter : <b>1.96 mm [ .077 in ]</b> |
| Usage Conditions                                                                                                                                                        | Operating Temperature Range (°C): <b>-65 – 200</b>                                                                                                                                                                                                                                             |
| Other                                                                                                                                                                   | Wire Source : <b>United States</b>                                                                                                                                                                                                                                                             |

Compatible Parts

> [Contact Product Support](#)

Also in the Series

CGS SP




Board-to-Board  
Connector Contacts  
(2)



Board-to-Board  
Headers &  
Receptacles (1)



Cable Actuated  
Position Sensors (17)

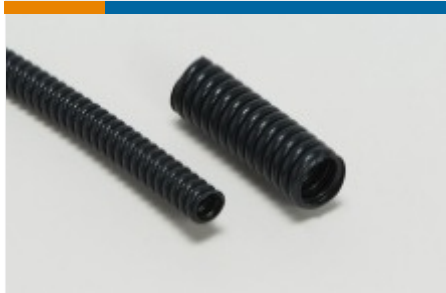

Convolute Tubing  
(15)

Feedback


Customers Also Bought






TE Part # 1-1757819-0  
AMPLIMITE, ASY,  
PLUG, STD, 109, ZN,  
5, CT

Add to Cart

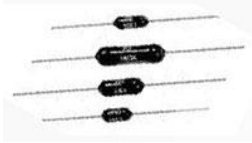

TE Part # H4P910RFZA  
H4P 910R 1% 100PPM

View Product

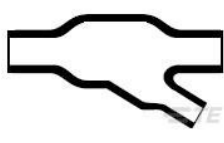

TE Part # 362A014-4-0  
362A014-4-0

View Product



TE Part # ACT26MD05SN  
[V001]  
STRAIGHT PLUG

View Product