


Home > Products > Wire & Cable > Product Feature Selector > Product Details

44A0121-24-0/2-US Product Details

 Share

 Print

 Email

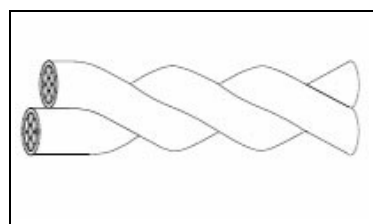

44A0121-24-0/2-US

TE Internal Number: 383760-002

 Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

 Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)

 [Request Sample](#)

 [Find Similar Products](#)

 [Buy Product](#)

Documentation & Additional Information	
Product Drawings: • TWO CONDUCTOR CABLE, UNSHIELDED, UNJACKETED, LIGHTWE... (PDF, English) Catalog Pages/Data Sheets: • None Available Product Specifications: • None Available Application Specifications: • None Available Instruction Sheets: • None Available CAD Files: • None Available	Related Products: • Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: • Cable Type = Spec 44 • Cable Style = Primary Electrical Characteristics: • Voltage Rating (VAC) = 600 Dimensions: • Conductor Outer Diameter (mm [in]) = 0.64 [0.025] Body Features: • Wire Size (AWG/CM) = 24 AWG • Conductor Type = Tin-Plated Copper • Wire Color = Black, Red • Nominal Outside Diameter (mm [in]) = 2.03 [0.080] • Wire Diameter (mm [in]) = 1.02 [0.040] Configuration Features: • Number of Conductors = Twisted Pair	Industry Standards: • Government/Industry Qualification = No • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Not relevant for lead free process • RoHS/ELV Compliance History = Always was RoHS compliant Conditions for Usage: • Temperature Range (°C) = -65 - +150 • Wire Size - Details = 24 AWG 0.24 mm², 0.00037 in², 19 x 36 AWG Operation/Application: • Application = General Purpose - Lightweight Packaging Features: • Wire Source = United States Other: • Brand = Raychem

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed



Feedback

