

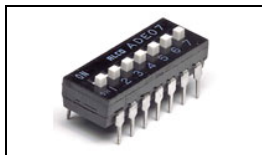


Have a Question?
Chat with a Product
Information Specialist

What can we help you find?

[Products](#) [Industries](#) [Resources](#) [About TE](#) [My Account](#) [Innovation](#) [Support Center](#)

1-1825058-9 Product Details

[Share](#)[Print](#)[Email](#)

1-1825058-9

(ADE08S04)

TE Internal Number: 1-1825058-9

Active

[View 3D PDF](#)

DIP & SIP Switches - Standard



Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- Switch
- Switch Type = DIP
- PCB Mount Style = Surface Mount
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Extended, Slide

[View all Features](#)

Quick Links

- [▶ Pricing & Availability](#)
- [▶ Search for Tooling](#)
- [▶ Product Feature Selector](#)
- [▶ Contact Us About This Product](#)

[Add to My Part List](#)

[Request Sample](#)

[Find Similar Products](#)

[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [DIP SWITCH, ADE-SMT SERIES](#) (PDF, English)

Catalog Pages/Data Sheets:

- [SWITCHES_CORE_PROGRAM_CATALOG](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version 0)
- [3D Model](#) (IGES, Version 0)
- [3D Model](#) (STEP, Version 0)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Switch
- [PCB Mount Style](#) = Surface Mount
- [Actuator Style](#) = Extended, Slide
- Sealed = No

Termination Features:

- Termination Style = Outside "L"

Body Features:

- Switch Type = DIP
- Actuator Color = White

Contact Features:

- Auto-Insertable = Yes
- Contact Base Material = Copper Alloy
- Contact Plating, Mating Area, Material = Gold Flash

Housing Features:

- Centerline (mm [in]) = 2.54 [0.100]
- Housing Color = Black
- Housing Material = Polyphenylene Sulfide (PPS)

Configuration Features:

- [Configuration \(Pole-Throw\)](#) = Single Pole - Single Throw
- [Number of Switches](#) = 8

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C, Reflow solder capable to 260°C
- RoHS/ELV Compliance History = Always was RoHS compliant
- UL Flammability Rating = UL 94V-0

Other:

- Series = AD
- Brand = TE Connectivity

Corporate Information

[About TE](#)

[Investors](#)

Quick Links

[Distributor Inventory](#)

[Product Cross Reference](#)

Customer Support

[Email or Chat With Us](#)

[Find a Phone Number](#)

[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)

[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

