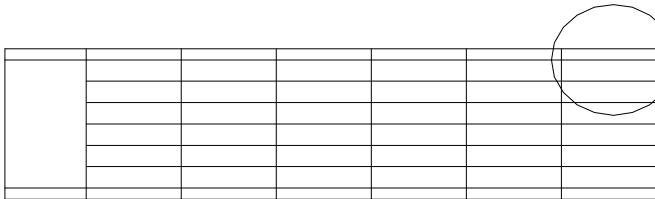
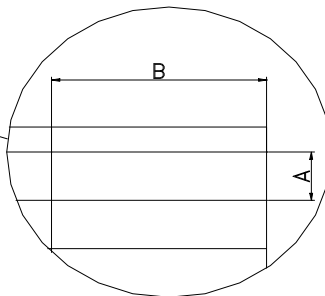


DATA SHEET DS/233		PRINT SYSTEM TAGS FOR SI2KPRINT1 THERMAL TRANSFER PRINTER						DATA 23/03/09	
GRAPHIC REPRESENTATION									
IN THE PICTURE AN EXAMPLE OF THE SI2K... ITEM						TAG'S DETAIL			
									
REFERENCE ITEM CODE									
SI2K0920W - SI2K0920Y - SI2K1001W- SI2K1001Y - SI2K0935W - SI2K0935Y - SI2K1517M - SI2K1517W - SI2K1517Y SI2K40720W - SI2K40720Y - SI2K40920W - SI2K40920Y - SI2K40935W - SI2K40935Y - SI2K41517M - SI2K41517W SI2K41517Y - SI2K40817W - SI2K40817Y - SI2K0730W - SI2K0730Y - SI2K40917W - SI2K40917Y									
APPLICATION					SERIES PROPERTIES				
Punched tags to mark with the thermal transfer printer SI2KPRINT1					SI2K...M - SI2K...M : silver color SI2K...W - SI2K...W : white color SI2K...Y - SI2K...Y : yellow color				
PHYSICAL PROPERTIES			ITEM SI2K.. (NOT SELF-ADHESIVE)			ITEM SI2K4.. (SELF-ADHESIVE)			
MATERIAL			PVC - Integral Polyvinyl chloride			PVC - Integral Polyvinyl chloride			
COLOR			Metal - White - Yellow			Metal - White - Yellow			
SELF-EXTINGUISHABILITY			V0 Class in compliance with UL 94 norms			V0 Class in compliance with UL 94 norms			
WATER ABSORPTION			0.08 % after 7 days			0.08 % after 7 days			
ADHESIVE MASS			/			ACRYLIC			
ADHESION TO STEEL (N/100 mm)			/			72			
OPERATIVE TEMPERATURE			-40 ÷ +60 °C (-40 ÷ +140 °F)			-40 ÷ +60 °C (-40 ÷ +120 °C for ADHESIVE)			
APPLICATION TEMPERATURE			/			+ 10 °C			
PVC / ADHESIVE THICKNESS			0,5 mm / NO			0,5 mm / 0,06 mm.			
ITEM CODE	SIZES				QUANTITY			COMPATIBILITY	
	A (mm)	B (mm)	SHEET LENGTH (mm)	SHEET WIDTH (mm)	TAGS x PACK	SHEET x PACK	TAGS x SHEET		
SI2K0730W/Y	7	30	220	62	1680	40	42		
SI2K0746W	7	46	230	56	1120	40	28	WAGO I/O 750	
SI2K0920W/Y	9	20	240	62	2400	40	60	160..... - 161....	
SI2K1001W/Y	9,3	20	240	62	2400	40	60	SI1001	
SI2K0935W/Y	9	35	240	62	1440	40	36	160..... - 161....	
SI2K1517M/W/Y	15	17	240	62	1560	40	39	SITOB15	
SI2K40720W/Y	7	20	240	62	1750	25	70	/	
SI2K40817W/Y	8	17	240	62	1925	25	77	/	
SI2K40917W/Y	9	17	240	62	1800	25	72	160..... - 161....	
SI2K40920W/Y	9	20	240	62	1500	25	60	/	
SI2K40935W/Y	9	35	240	62	900	25	36	/	
SI2K41517M/W/Y	15	17	240	62	975	25	39	/	
NOTES: THE ITEMS SI2K40720W - SI2K40720Y CAN MARK THE SIEMENS SERIUS 3R CONTACTORS. ITEM SI2K40817W- Y MAY BE USED TO MARK TESYS TELEMECANIQUE CONTACTORS.									
Document	REVIEWED, APPR. BY:			DATE:	REVISION OBJECT			PAGES:	
78-8127-9060-4								1 of 1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

3M:

[SI1002](#) [SI2K0730W](#) [SI2K0730Y](#) [SI2K0746W](#) [SI2K0827W](#) [SI2K0920W](#) [SI2K0920Y](#) [SI2K0935W](#) [SI2K0935Y](#)
[SI2K1001W](#) [SI2K1001Y](#) [SI2K1517W](#)