


Ring Tongues – Vinyl Insulated Butted Seam 22-18 AWG

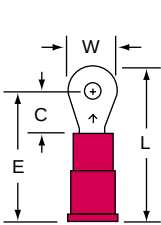


Product Number†	Wire UPC (054007-)	Range (AWG)	Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Maximum Insulation Diameter	Terminals per Case
MVU18-2R/SK	01077	22-18	2	0.25	0.22	0.80	0.67	0.030	0.25	0.070	0.145	1000
MVU18-4R/SK	01078	22-18	4	0.25	0.22	0.80	0.67	0.030	0.25	0.070	0.145	1000
MVU18-6R/SK	01080	22-18	6	0.25	0.22	0.80	0.67	0.030	0.25	0.070	0.145	1000
MVU18-8R/LK	01085	22-18	8	0.31	0.33	0.93	0.78	0.030	0.25	0.070	0.145	1000
MVU18-10R/LK	01087	22-18	10	0.31	0.33	0.93	0.78	0.030	0.25	0.070	0.145	1000
MVU18-14R/SK	01088	22-18	1/4	0.47	0.40	1.08	0.85	0.030	0.25	0.070	0.145	1000
MVU18-516R/SK	01090	22-18	5/16	0.47	0.40	1.08	0.85	0.030	0.25	0.070	0.145	1000
MVU18-38RK	01092	22-18	3/8	0.56	0.40	1.13	0.85	0.030	0.25	0.070	0.145	1000




MVU18-2R/S
2
22-18


Stud Size
Wire Range

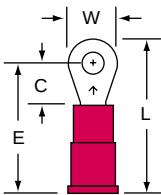


MVU18-4R/S
4
22-18

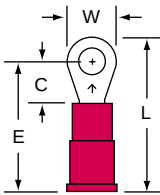

MVU18-6R/S
6
22-18

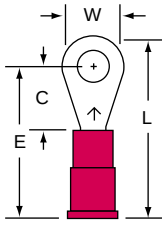


MVU18-8R/L
8
22-18

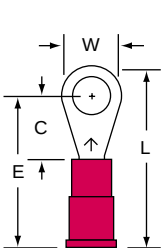


MVU18-10R/L
10
22-18


Stud Size
Wire Range

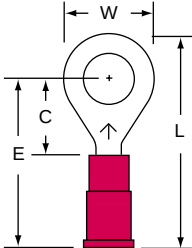

MVU18-14R/S
1/4
22-18

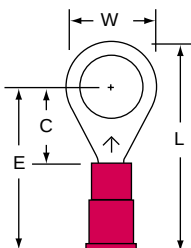

MVU18-516R/S
5/16
22-18

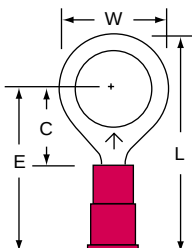

MVU18-38R
3/8
22-18

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

3M:

[MVU18-8R/LK](#) [MVU18-4R/SK](#) [MVU18-6R/SK](#) [MVU18-14R/SK](#) [MVU18-38RK](#) [MVU18-516R/SK](#)