

K&B Vault and Riser Closures

K&B Vault Closures

K&B closures are strong, lightweight, and protect a wide variety of vault splice configurations through an air tight/water tight seal. K&B closures offer a full product line that is simple to install and re-enter. This full product offering provides both “kitted” closures to protect the majority of cable configurations, and also the ability to customize your closure to meet virtually all your vault requirements.

These closures are flame retardant, **RUS listed** and UL approved.


Specifying and ordering K&B Vault Closures

The key to ordering the correct closure kit is knowing it’s components and making sure it suits the splice configuration. The kit includes a solid or split sleeve, collared end cap, multiple end cap, stainless steel hose clamps and cable lubricant.

The following will list the steps required to select either a “K&B Standard Closure Kit” or a set of “K&B Closure Components” to meet your vault closure needs.

Step 1:

Identify pair count and outside diameters of all main and tip cables. Fill in the splice data into the sketched diagram describing your closure requirements.

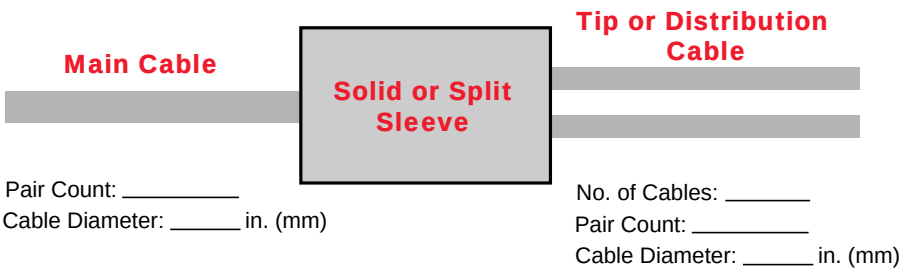

The standard K&B Splice Closure Kit contains the following:

- 1 - Solid or Split Sleeve
- 1 - Collared End Cap
- 1 - Multiple End Cap
- 1 - Cable Lubricant
- 3 - Stainless Steel Hose Clamps

Note: The KB2-100-2 uses two C2-2 Butt Caps, while both KB3-175-1 and KB4-175-1 have two Collared End Caps.

Step 2:

Using “Chart A,” determine the appropriate sleeve diameter that will accommodate the splice based on the pair count and type of connector used. For example, a 600-pair cable spliced with MS™ Modules or a 300-pair cable spliced with Scotchlok™ Connectors will require a 5-inch diameter sleeve (refer to the first 3 columns). KB5 of kit part number KB5-130-6 under column 4 denotes a 5-inch diameter solid sleeve. The 130-6 indicates a 1.30 inch diameter for each of the 6 outgoing tip cable ports. Select a closure kit with a solid sleeve (KB5) for new construction or a split sleeve (KBS5) for existing splices.

Chart A K&B Standard Closure Kits



			Standard closure kits		End cap configurations		
			 218	 219	 220	 226	 221
Pair Count	Sleeve						
MS²	Scotchlok	Diameter in. (mm)	Solid Sleeve Kit part number	Split Sleeve Kit part number	Collared Part number	Collared Part number	Multiple Part number
100	50	2 (51)	KB2-100-2		C2-2 (two)		
200	100	3 (76)	KB3-175-1	KBS3-175-1	C3-175-1C (two)	C3-175-1C	
400	200	4 (102)	KB4-175-1 KB4-175-2		C4-175-1C (two) C4-175-1C	C4-175-C	C4-175-2
600	300	5 (127)	KB5-100-6 KB5-130-6 KB5-175-2	KBS5-100-6 KBS5-130-6 KBS5-175-2	C5-275-1C C5-275-1C C5-275-1C	C5-275-1C	C5-100-6 C5-130-6 C5-175-2
900	400	6 (152)	KB6-100-9 KB6-130-9 KB6-175-3	KBS6-100-9 KBS6-130-9 KBS6-175-3	C6-275-1C C6-275-1C C6-275-1C	C6-275-1C	C6-100-9 C6-130-9 C6-175-3
1200	600	7 (178)	KB7-100-15 KB7-175-5	KBS7-100-15 KBS7-175-5	C7-275-1C C7-275-1C	C7-275-1C	C7-100-15 C7-175-5
2400	800	8 (203)	KB8-100-24 KB8-130-18 KB8-175-8	KBS8-100-24 KBS8-130-18 KBS8-175-8	C8-300-1C C8-300-1C C8-300-1C	C8-300-1C	C8-100-24 C8-130-18 C8-175-8
2700	900	9 (229)	KB9-100-27 KB9-130-24 KB9-175-9	KBS9-100-27 KBS9-130-24 KBS9-175-9	C9-300-1C C9-300-1C C9-300-1C	C9-300-1C	C9-100-27 C9-130-24 C9-175-9
3600	—	10 (254)	KB10-100-36 KB10-100-36L	KBS10-100-36 KBS10-100-36L	C10-360-1C C10-360-1C	C10-360-1C	C10-100-36 C10-100-35
4800	—	12 (305)	KB12-130-37		C12-390-1C	C12-100-48 C12-130-37	C12-130-37


Step 3:

Choose the correct Collared and multiple end caps to meet your cable diameter and configuration. (Refer to end cap configurations in Chart A).

End Cap Examples:


Collared Caps (for main cable):

C5-275-1C

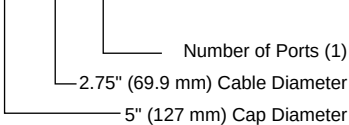

Multiple Caps (for tip cable):

C5-100-6

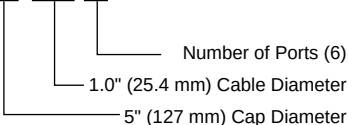

Determine if a standard closure will work by comparing the number of tip cables and their diameters with the ports in the standard multiple end caps. (e.g. C8-130-18). The collared cap ports can be up to 1/4" larger than the nominal cable diameter. Use bushings for further reduction. Plug any unused holes by selection tapered plugs. (Refer to Chart C).



Product Referral Generator

MS²™ Modules	pg. 6
Cable Cleaning	pg. 127
Sheath Scuff	pg. 128
Shield Bonding	pg. 129
Pressure Blocking	pg. 120
Duct Sealing	pg. 119
Scotchlok™ Connectors	pg. 2
Cable Ties	pg. 135

Step 4:

If an appropriate Standard Closure Kit can be identified, place your order using the Closure Kit Part Number under columns 4 and 5 in Chart A or Stock Number found on page 112, otherwise continue the following steps to “customize” your vault closure using K&B Closure components found in Chart B.

Chart B K&B Closure Component Selector Guide



Sleeves		End caps				
 222	 223	 224	 225	 226	 227	 228
Solid Diameter length Part number	Split Diameter length Part number	Butt Part number	Flat Part number	Collared Part number	Multiple Part number	Puddle Part number
2-24	2DS-24	C2-2	C2			
3-24	3DS-24	C3-3	C3	C3-175-1C		
4-24	4DS-24		C4	C4-175-1C	C4-175-2	
5-26	5DS-26		C5	C5-275-1C	C5-100-6 C5-130-6 C5-175-2	
6-26	6DS-26		C6	C6-275-1C	C6-100-9 C6-100-10 C6-130-9 C6-175-3	
7-26	7DS-26		C7	C7-275-1C	C7-100-15 C7-175-5	C7-5
8-26	8DS-26		C8	C8-300-1C	C8-100-24 C8-130-18 C8-178-8	C8-7
9-26	9DS-26		C9	C9-300-1C	C9-100-27 C9-130-24 C9-175-9 C9-275-3	C9-5 C9-7
10-26 10-34	10DS-26 10DS-34		C10	C10-360-1C	C10-100-27 C10-100-36	C10-8
12-28	12SS-28		C12	C12-390-1C	C12-100-48 C12-130-37	C12-8/6

To complete the closure kit, include the additional K&B accessories in your order from the following pages once the end seals and sleeve components are selected.

Step 5:

The K&B Flat End Caps can be customized if neither the Closure Kits or the Component End Caps meet your cable requirements. Use your measured cable diameter to specify the required bushing from “Chart C” and specify the number of holes to be drilled by the factory when ordering your customized end caps. The custom end caps will be shipped with holes drilled in the flat cap and bushings inserted and cemented. If the end cap is used to maintain an existing splice, the end cap holes need to be slit in order to install the end cap. Both split and solid sleeves can be factory cut for your desired length. The following chart lists the stock numbers to be used when ordering customized sleeve or end cap holes and slits.

Customized K&B Closure Components	Stock Number	UPC
Closure Sleeves Split and Solid	80-6103-2771-2	63999
End Cap Hole	78-8011-5552-0	26544
End Cap Hole Split	78-8011-5553-8	26545

Step 6:

Order two collared clamps for a solid sleeve or three for a split sleeve. Also specify a hose clamp for each collared end opening. (Refer to Chart D).

Step 7:

Complete the closure by specifying Cable Lubricant and any required accessories such as tape or splice supports (RC-100’s).

K&B Closure Accessory Products

Bushings. Variable and standard rubber bushings are used with collared, multiple, and customized flat end caps to reduce the end seal’s cable openings diameter to match your required cable diameter. “Chart C” lists both bushing types and their respective cable sizes. **Collared plugs.** Rubber, cup-shaped collared plugs are used to plug unwanted openings on collared or butt end caps. They may be removed as additional cables are required. **Tapered plugs.** Tapered plugs are used to close unwanted tip cable entrances on multiple caps.

Chart C

K&B Bushings and Plugs

inches (mm) *If inside diameter is less than 0.2, use DBS-1 to seal.



 
 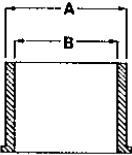
Rubber Bushings	Dimensional Diagram	Part Number	Dimension A	Dimension B	Dimension C	Dimension D
 229		B-100-50	1.04 (26.4)	0.5 (13)	0.85 (20.8)	
 230		B-100-70 B-125-100	1.0 (28) 1.25 (32)	0.92 (23.4) 1.06 (26.9)	0.62 (15.7) 0.85 (21.8)	
 231		B-175-125 B-175-150 B-225-175 B-225-200 B-275-200 B-275-225 B-275-250 B-300-275 B-360-300 B-360-330 B-390-360	1.75 (44) 1.75 (44) 2.25 (57) 2.25 (57) 2.75 (70) 2.75 (70) 2.75 (70) 2.75 (70) 3.0 (76) 3.6 (91) 3.6 (91) 3.9 (99)	1.25 (32) 1.5 (38) 1.75 (44) 2.0 (51) 2.0 (51) 2.25 (57) 2.5 (64) 2.75 (70) 3.0 (76) 3.3 (84) 3.6 (91)		
Variable Bushings						
 232		B-1.00-0.25 B-2.50-1.00	0.49 (12.4) 1.0 (25.4)	0.69 (17.5) 1.40 (35.6)	0.79 (20.1) 1.90 (48.3)	1.0 (25.4) 2.50 (63.5)
 233		B-1.75-1.50-1.00	1.12 (28.4)	1.50 (38.1)	1.75 (44.5)	
Plugs						
 234		Collared PC-175 PC-225 PC-275 PC-298	1.75 (44) 2.25 (57) 2.75 (70) 2.98 (76)			
		Tapered PT-100 PT-120 PT-125 PT-130 PT-175 PT-225	1.0 (25) 1.2 (31) 1.25 (32) 1.3 (33) 1.75 (44) 2.25 (57)	0.75 (19) 1.25 (32) 1.75 (44)		

Chart D K&B Clamps and Sleeves The following lists the sleeve and clamp part numbers

Closure Part number	Sleeve Diameter inches (mm)Part number	Clamp (1 each) Part number	Collared Clamp (2 each)
KB2	2 (51)	2SS	
KB3	3 (76)	3SS	3-4CC
KB4	4 (102)	4SS	3-4CC
KB5	5 (127)	5SS	5-9CC
KB6	6 (152)	6-7SS	5-9CC
KB7	7 (178)	6-7SS	5-9CC
KB8	8 (203)	8SS	5-9CC
KB9	9 (229)	9-10SS	5-9CC
KB10	10 (254)	9-10SS	10-12CC
KB12	12 (305)	12SS	10-12CC

 Bonding Harness



235

For use in closure to ground shields of spliced cable; 14 AWG.

Cable Lubricant



236

Designed to make vault closure installation faster by lubricating tip cables before insertion into multiple end caps, the cable lubricant evaporates after use and does not damage closure elements in any way. Supplied in a 113.2 g (4 oz.) dauber-top bottle.

5925 Fire Barrier Vault Rehabilitation Kit



237

For use in conjunction with an existing vertically installed K&B Vault Closure when required to meet specific fire retardancy requirements such as the Bell System Technical Reference PUB 55006 (Issue 1, Section 5.53).

Kit Contents/Size:

- Fire Barrier Foil Mat
298 mm x 3.7 m (11 3/4" x 12')
- No. 69 Glass Cloth Tape
25 mm x 23 m (1" x 25 yds.)

KB-S1 Sealing Kit



238

KB-S1 is designed for sealing split K&B vault sleeves and split end caps. Each kit contains a "Mini-Semkit" of 38 g of urethane adhesive, a 50.8 mm x 76.2 mm x 9.5 mm (2" x 3" x 3/8") ScotchBrite 7H Pad, a wooden spatula, and instructions.


K&B Vault Closure Rehabilitation Kit



240

This kit is designed for use in repairing damaged or improperly installed multiple end caps in K&B Vault Closures. Kit contains expandable foam sealant, clear plastic strip, and pieces of foam to rehabilitate the tip end of the closure.

RC-100 Splice Supports

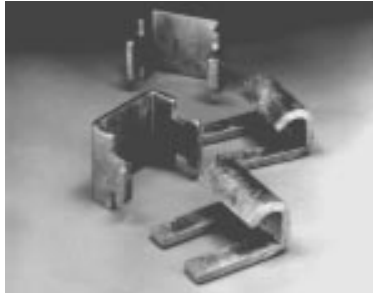

239

Designed to reduce closure support costs. The rack clips permit fast, multi-positioning of industry standard manhole racks or uni-struts and hooks to facilitate support of a closure. Two supports per set.

K&B Building Riser Closures

Proven K&B quality. Closure kits are specifically designed for riser applications. . . five kits that will meet just about every riser application you'll ever run across. And that's going to simplify your ordering, your inventory, and your training procedures. Closures and end caps are flame retardant.

R-3/R-5 Multiple Entry Kits

- Kit contents:
- Closure Cover Halves (2)
 - Double entry conical end caps (2)
 - Stainless steel hose clamps (2)
 - Flex strips (4)

R-7/R-9 Multiple Entry Kits

- Kit contents:
- Closure Cover Halves (2)
 - Triple entry conical end caps (2)
 - Stainless steel hose clamps (2)
 - Flex strips (4)
- Single port SRC end caps are optional, and must be ordered separately.



242

Riser closure end caps — Single entry (optional)



243

SRC-3	Riser Closure End Cap	3 (76)
SRC-5	Riser Closure End Cap	5 (127)
SRC-7	Riser Closure End Cap	7 (178)
SRC-9	Riser Closure End Cap	9 (229)

Multiple Entry Closures (Straight Inline Splices with MS²™ Super-Mini Modules)

mm (inches)

Product number	R-3	R-5	R-7	R-9
Closure inside dimensions				
Diameter	76 (3)	127 (5)	178 (7)	228 (9)
Length	24 (607)	660 (26)	660 (26)	660 (26)
Approx. splice bundle capacity (Super-Mini)	300-pr. 24 AWG or less	900-pr. 24 AWG	1800-pr. 24 AWG	3000-pr. 26 AWG
Maximum allowable cable diameter				
Multiple entry end caps				
Port 1	30 (1.2)	51 (2.0)	79 (3.1)	96 (3.8)
Port 2	30 (1.2)	51 (2.0)	61 (2.4)	79 (3.1)
Port 3	—	—	51 (2.0)	61 (2.4)
Optional single entry end caps	SRC-3 43 (1.7)	SRC-5 61 (2.4)	SRC-7 91 (3.6)	SRC-9 96 (3.8)

R-6 10 Port/Single Entry Kit



241

- Kit contents:
- Closure Cover Halves (2)
 - Single entry conical end cap
 - 10-port rubber end cap
 - Stainless steel hose clamps (2)
 - 4 fl. oz. (120 ml) bottle of cable lubricant
- The R-6 is intended for use on new construction only.

10-Port Single Entry Kit

Product number	R-6
Closure inside dimensions	mm (inches)
Diameter	152 (6)
Length	660 (26)
Approx. splice bundle capacity (Super-Mini)	900 pr. 24 AWG
Maximum allowable cable diameter	
Multiple entry end cap (ports 1-10)	28 (1.1)
Single entry end cap	84 (3.3)

Ordering Information for K&B Vault Closure Kits

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
KB2-100-2	1/cs., .91 (2.0)/cs.	1 each	26818
KB3-175-1	1/cs., 1.81 (4.0)/cs.	1 each	26820
KB4-175-1	1/cs., 2.27 (5.0)/cs.	1 each	26822
KB4-175-2	1/cs., 2.27 (5.0)/cs.	1 each	26823
KB5-100-6	1/cs., 2.27 (5.0)/cs.	1 each	26825
KB5-130-6	1/cs., 2.27 (5.0)/cs.	1 each	26826
KB5-175-2	1/cs., 2.27 (5.0)/cs.	1 each	26827
KB6-100-9	1/cs., 3.63 (8.0)/cs.	1 each	26829
KB6-130-9	1/cs., 3.63 (8.0)/cs.	1 each	26830
KB6-175-3	1/cs., 3.63 (8.0)/cs.	1 each	26831
KB7-100-15	1/cs., 3.63 (8.0)/cs.	1 each	26833
KB7-175-5	1/cs., 5.90 (13.0)/cs.	1 each	26834
KB8-100-24	1/cs., 7.26 (16.0)/cs.	1 each	26381
KB8-130-18	1/cs., 7.26 (16.0)/cs.	1 each	26382
KB8-175-8	1/cs., 7.26 (16.0)/cs.	1 each	26464
KB9-100-27	1/cs., 7.26 (16.0)/cs.	1 each	26465
KB9-130-24	1/cs., 8.16 (18.0)/cs.	1 each	26466
KB9-175-9	1/cs., 8.16 (18.0)/cs.	1 each	26504
KB10-100-36	1/cs., 9.07 (20.0)/cs.	1 each	26624
KB10-100-36L	1/cs., 9.07 (20.0)/cs.	1 each	26505
KB12-130-37	1/cs., 12.70 (28.0)/cs.	1 each	26507

Ordering Information for K&B Vault Closure Kits with Split Sleeve

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
KBS3-175-1	1/cs., 1.81 (4.0)/cs.	1 each	26835
KBS5-100-6	1/cs., 2.27 (5.0)/cs.	1 each	26837
KBS5-130-6	1/cs., 2.27 (5.0)/cs.	1 each	26838
KBS5-175-2	1/cs., 2.27 (5.0)/cs.	1 each	26839
KBS6-100-9	1/cs., 3.63 (8.0)/cs.	1 each	26841
KBS6-130-9	1/cs., 3.63 (8.0)/cs.	1 each	26842
KBS6-175-3	1/cs., 3.63 (8.0)/cs.	1 each	26843
KBS7-100-15	1/cs., 5.9 (13.0)/cs.	1 each	26845
KBS7-175-5	1/cs., 5.9 (13.0)/cs.	1 each	26846
KBS8-100-24	1/cs., 7.26 (16.0)/cs.	1 each	26566
KBS8-130-18	1/cs., 7.26 (16.0)/cs.	1 each	26567
KBS8-175-8	1/cs., 7.26 (16.0)/cs.	1 each	26568
KBS9-100-27	1/cs., 8.16 (18.0)/cs.	1 each	26569
KBS9-130-24	1/cs., 8.16 (18.0)/cs.	1 each	26570
KBS9-175-9	1/cs., 8.16 (18.0)/cs.	1 each	26571
KBS10-100-36 26"	1/cs., 9.07 (20.0)/cs.	1 each	26572
KBS10-100-36L 34"	1/cs., 9.07 (20.0)/cs.	1 each	26573

Ordering Information for K&B Solid Sleeves



Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
3-24	1/cs., .45 (1.0)/cs.	1 each	26819
4-24	1/cs., .91 (2.0)/cs.	1 each	26821
5-26	1/cs., .91 (2.0)/cs.	1 each	26824
6-26	1/cs., 1.36 (3.0)/cs.	1 each	26828
7-26	1/cs., 2.27 (5.0)/cs.	1 each	26832
8-26	1/cs., 2.72 (6.0)/cs.	1 each	26356
9-26	1/cs., 3.18 (7.0)/cs.	1 each	26357
10-26	1/cs., 3.18 (7.0)/cs.	1 each	26623
10-34	1/cs., 3.18 (7.0)/cs.	1 each	26358
12-28	1/cs., 4.54 (10.0)/cs.	1 each	26359

Ordering Information for K&B Split Sleeves



Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
2DS-24	1/cs., .45 (1.0)/cs.	1 each	26498
3DS-24	1/cs., .45 (1.0)/cs.	1 each	26499
4DS-24	1/cs., 1.36 (3.0)/cs	1 each	26500
5DS-26	1/cs., 1.36 (3.0)/cs.	1 each	26836
6DS-26	1/cs., 1.81 (4.0)/cs.	1 each	26840
7DS-26	1/cs., 2.27 (5.0)/cs.	1 each	26844
8DS-26	1/cs., 3.18 (7.0)/cs.	1 each	26501
9DS-26	1/cs., 3.63 (8.0)/cs.	1 each	26502
10DS-26	1/cs., 3.63 (8.0)/cs.	1 each	26503
10DS-34	1/cs., 3.63 (8.0)/cs.	1 each	26574
12SS-28	1/cs., 4.99 (11.0)/cs.	1 each	26693

Ordering Information for K&B Multiple Caps



Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C4-175-2	1/cs., .34 (.75)/cs	1 each	26420
C5-100-6	1/cs., 0.68 (1.5)/cs.	1 each	26402
C5-130-6	1/cs., 0.68 (1.5)/cs.	1 each	26403
C5-175-2	1/cs., 0.45 (1.0)/cs.	1 each	26404
C6-100-9	1/cs., 0.79 (1.75)/cs.	1 each	26405
C6-100-10	1/cs., 0.79 (1.75)/cs.	1 each	26690
C6-130-9	1/cs., 0.9 (2.0)/cs.	1 each	26406
C6-175-3	1/cs., 1.1 (2.5)/cs.	1 each	26407
C7-100-15	1/cs., 1.2 (2.75)/cs.	1 each	26408
C7-175-5	1/cs., 1.1 (2.5)/cs.	1 each	26409
C8-100-24	1/cs., 1.7 (3.75)/cs.	1 each	26410
C8-130-18	1/cs., 1.6 (3.5)/cs.	1 each	26411
C8-175-8	1/cs., 1.6 (3.5)/cs.	1 each	26412
C9-100-27	1/cs., 1.7 (3.75)/cs.	1 each	26413
C9-130-24	1/cs., 1.6 (3.5)/cs.	1 each	26414

Ordering Information for K&B Multiple Caps (cont.)

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C9-175-9	1/cs., 1.6 (3.5)/cs.	1 each	26415
C9-275-3	1/cs., 1.4 (3.0)/cs.	1 each	26853
C10-100-27/300 ESS	1/cs., 2.3 (5.0)/cs.	1 each	26689
C10-100-36	1/cs., 2.3 (5.0)/cs.	1 each	26513
C12-130-37	1/cs., 3.1 (6.75)/cs.	1 each	26497
C12-100-48	1/cs., 3.1 (6.75)/cs.	1 each	26697

Ordering Information for K&B Butt Caps

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C2-2	1/cs., 0.06 (0.13)/cs.	1 kit	26418
C3-3	1/cs., 0.09 (0.19)/cs.	1 kit	26419

Ordering Information for K&B Collared End Caps

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C3-175-1C	1/cs., 0.23 (0.5)/cs.	1 each	26532
C4-175-1C	1/cs., 0.34 (0.75)/cs.	1 each	26533
C5-275-1C	1/cs., 0.91 (2.0)/cs.	1 each	26534
C6-275-1C	1/cs., 0.91 (2.0)/cs.	1 each	26535
C7-275-1C	1/cs., 1.13 (2.5)/cs.	1 each	26536
C8-300-1C	1/cs., 1.36 (3.0)/cs.	1 each	26537
C9-300-1C	1/cs., 1.59 (3.5)/cs.	1 each	26538
C10-360-1C	1/cs., 1.59 (3.5)/cs.	1 each	26539
C12-390-1C	1/cs., 2.49 (5.5)/cs.	1 each	26540

Ordering Information for K&B Flat Caps

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C2 (2")	1/cs., 0.09 (0.19)/cs.	1 each	26383
C3 (3")	1/cs., 0.09 (0.19)/cs.	1 each	26384
C4 (4")	1/cs., 0.23 (0.5)/cs.	1 each	26385
C5 (5")	1/cs., 0.45 (1.0)/cs.	1 each	26698
C6 (6")	1/cs., 0.45 (1.0)/cs.	1 each	26699
C7 (7")	1/cs., 0.45 (1.0)/cs.	1 each	26700
C8 (8")	1/cs., 0.9 (2.0)/cs.	1 each	26701
C9 (9")	1/cs., 1.4 (3.0)/cs.	1 each	26702
C10 (10")	1/cs., 1.4 (3.0)/cs.	1 each	26703
C12 (12")	1/cs., 2.3 (5.0)/cs.	1 each	26704

Ordering Information for K&B Puddle Caps



Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
C7-5	1/cs., 0.91 (2.0)/cs.	1 each	26422
C8-7	1/cs., 0.91 (2.0)/cs.	1 each	26696
C9-5	1/cs.,1.36 (3.0)/cs.	1 each	26423
C9-7	1/cs., 0.91 (2.0)/cs.	1 each	26424
C10-8	1/cs., 1.81 (4.0)/cs.	1 each	26695
c12-8/6	1/cs., 1.27 (5.0)/cs.	1 each	26852

Ordering Information for K&B Bushings



Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
B100-50	1/cs., 0.09 (3)/cs.	1 each	26446
B100-70	1/cs., 0.09 (3)/cs.	1 each	27182
B125-100	1/cs., 0.03 (1)/cs.	1 each	26692
B175-125	1/cs., 0.06 (2)/cs.	1 each	26528
B175-150	1/cs., 0.06 (2)/cs.	1 each	26527
B225-175	1/cs., 0.09 (3)/cs.	1 each	26519
B225-200	1/cs., 0.17 (6)/cs.	1 each	27185
B275-200	1/cs., 0.17 (6)/cs.	1 each	26520
B275-225	1/cs., 0.11 (4)/cs.	1 each	26521
B275-250	1/cs., 0.06 (2)/cs.	1 each	26522
B300-275	1/cs., 0.09 (3)/cs.	1 each	26523
B360-300	1/cs., 0.11 (4)/cs.	1 each	26524
B360-330	1/cs., 0.11 (4)/cs.	1 each	26525
B390-360	1/cs., 0.11 (4)/cs.	1 each	26526

Ordering Information for K&B Variable Bushings



Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
B-1.0-2.5	1/cs., 0.09 (3)/cs.	1 each	26461
B-2.5-1.0	1/cs., 0.09 (3)/cs.	1 each	26462
B-1.75-1.50-1.0	1/cs., 0.09 (3)/cs.	1 each	26360

Ordering Information for K&B Tapered Plugs

Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
PT-100	1/cs. 0.03 (1)/cs.	1 each	17602
PT-120	1/cs. 0.03 (1)/cs.	1 each	26441
PT-125	1/cs. 0.03 (1)/cs.	1 each	26440
PT-130	1/cs. 0.06 (2)/cs.	1 each	17603
PT-175	1/cs. 0.06 (2)/cs.	1 each	26443
PT-225	1/cs. 0.09 (3)/cs.	1 each	26444

Ordering Information for K&B Collared Plugs

Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
PC-175	1/cs., 0.06 (2)	1 each	26433
PC-225	1/cs., 0.09 (3)	1 each	26434
PC-275	1/cs., 0.14 (5)	1 each	26436
PC-298	1/cs., 0.17 (6)	1 each	26438

Ordering Information for K&B Collared Cap Clamps

Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
3-4CC	1/cs., 0.03 (1)/cs.	1 each	26076
5-9CC	1/cs., 0.03 (1)/cs.	1 each	26077

Ordering Information for K&B Closure Clamps

Product number	Packaging kg (oz.)	Minimum order	UPC 054007-
2SS	1/cs., 0.03 (1)/cs.	1 each	26079
3SS	1/cs., 0.03 (1)/cs.	1 each	26078
4SS	1/cs., 0.03 (1)/cs.	1 each	26080
5SS	1/cs., 0.06 (2)/cs.	1 each	26081
6-7SS	1/cs., 0.09 (3)/cs.	1 each	17598
8SS	1/cs., 0.11 (4)/cs.	1 each	17611
9-10SS	1/cs., 0.11 (4)/cs.	1 each	26104
12SS	1/cs., 0.11 (4)/cs.	1 each	26105

Ordering Information for K&B Bonding Harnesses

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
BH2-6	1/cs., 0.23 (0.5)/cs.	1 set	26362
BH7	1/cs., 0.45 (1.0)/cs.	1 set	26363
BH8-9	1/cs., 0.68 (1.5)/cs.	1 set	26365
BH 10-12	1/cs., 0.91 (2.0)/cs.	1 set	26366

Ordering Information for K&B Building Riser Closure Kits

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
R3 DC/DC (Double Cap/Double Cap)	10/cs., 11.62 (25.6)/cs.	10 kits	33484
R5 DC/DC (Double Cap/Double Cap)	1/cs., 2.86 (6.3)/cs.	1 each	33485
R7 TC/TC (Triple Cap/Triple Cap)	1/cs., 4.18 (9.2)/cs.	1 each	33486
R9 TC/TC (Triple Cap/Triple Cap)	1/cs., 5.08 (11.2)/cs	10 kits	33487
R6 SC (Multiple Port End Cap)	1/cs., 4.63 (10.2)/cs.	1 each	33488

Ordering Information for K&B Riser Closure End Caps-Single Entry

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
SRC3 (3")	10/cs., 1.22 (2.7)/cs.	10 each	33490
SRC5 (5")	10/cs., 2.8 (6.1)/cs.	10 each	33491
SRC7 (7")	1/cs., 0.63 (1.4)/cs.	1 each	33493
SRC9 (9")	1/cs., 0.77 (1.7)/cs.	1 each	33489

Ordering Information for K&B Accessories

Product number	Packaging kg (lbs.)	Minimum order	UPC 054007-
5925 Fire Barrier Vault Rehabilitation Kit	1/cs., 4.0 (8.9)/cs.	1 kit	02438
RC-100 Splice Supports	10 sets/cs., 3.5 (7.8)/cs.	10 sets [521781]	31713
KB-S1 Sealing Kit	1 kit/cs., 0.15 (0.33)/cs.	1 kit	31101
Cable Lubricant	1/cs., 0.11 (0.25)/cs.	1 bottle	26512

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[3M:](#)

[R-3](#) [R-5](#) [R-6](#) [R-7](#)