


Ring Tongues – Non-Insulated Brazed Seam 6 AWG


Product Number [†]	UPC (054007-)	Wire Range (AWG)	Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Terminals per: Carton Case	
M6-10R/SX M6-10R/SK	24175 02147	6 6	10 10	0.47 0.47	0.52 0.52	1.14 1.14	0.91 0.91	0.050 0.050	0.39 0.39	0.250 0.250	20 —	200 200
M6-14R/SX M6-14R/SK	24183 02149	6 6	1/4 1/4	0.47 0.47	0.52 0.52	1.14 1.14	0.91 0.91	0.050 0.050	0.39 0.39	0.250 0.250	20 —	200 200
M6-516RX M6-516RK	24191 02151	6 6	5/16 5/16	0.63 0.63	0.52 0.52	1.22 1.22	0.91 0.91	0.050 0.050	0.39 0.39	0.250 0.250	20 —	200 200
M6-38RX M6-38RK	24209 02152	6 6	3/8 3/8	0.63 0.63	0.52 0.52	1.22 1.22	0.91 0.91	0.050 0.050	0.39 0.39	0.250 0.250	20 —	200 200
M6-12R/SK	02155	6	1/2	0.81	0.63	1.42	1.02	0.050	0.39	0.250	—	200

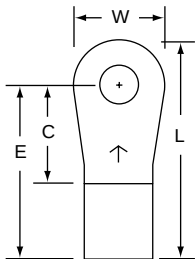

M6-10R/S


Stud Size
Wire Range

10
6

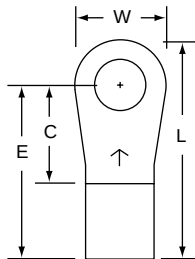


M6-14R/S

1/4
6

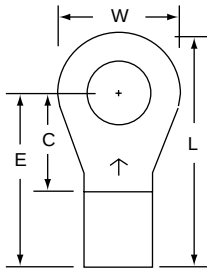


M6-516R

5/16
6

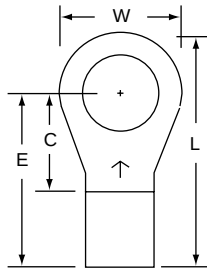

M6-38R

3/8
6

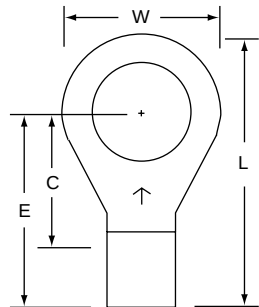

M6-12R/S

1/2
6

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

3M:

[M6-38RX](#) [M6-10R/SX](#) [M6-14R/SX](#) [M6-516RX](#)