


Ring Tongues – Non-Insulated Brazed Seam 8 AWG

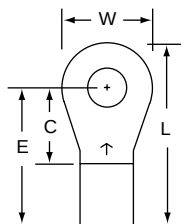


Product Number†	UPC (054007-)	Wire Range (AWG)	Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Terminals per: Carton	Case
M8-10R/SX M8-10R/SK	24118 02118	8 8	10 10	0.47 0.47	0.40 0.40	0.95 0.95	0.72 0.72	0.050 0.050	0.31 0.31	0.175 0.175	25 —	250 200
M8-14R/SX M8-14R/SK	24126 02120	8 8	1/4 1/4	0.47 0.47	0.40 0.40	0.95 0.95	0.72 0.72	0.050 0.050	0.31 0.31	0.175 0.175	25 —	250 200
M8-516RX M8-516RK	24134 02122	8 8	5/16 5/16	0.59 0.59	0.45 0.45	1.06 1.06	0.77 0.77	0.050 0.050	0.31 0.31	0.175 0.175	25 —	250 200
M8-38RX M8-38RK	24142 02123	8 8	3/8 3/8	0.59 0.59	0.45 0.45	1.06 1.06	0.77 0.77	0.050 0.050	0.31 0.31	0.175 0.175	25 —	250 200
M8-12R/SK	02126	8	1/2	0.81	0.69	1.41	1.00	0.050	0.31	0.175	—	200




M8-10R/S

Stud Size
Wire Range
10
8

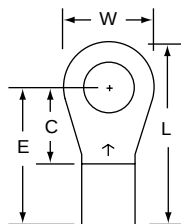


M8-14R/S

1/4
8

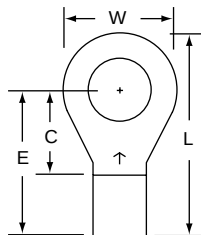


M8-516R

5/16
8

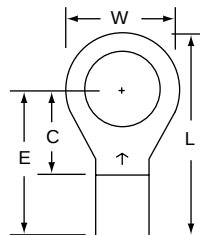

M8-38R

3/8
8

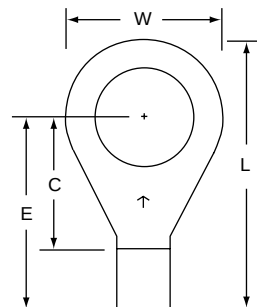

M8-12R/S

1/2
8

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

3M:

[M8-516RX](#) [M8-38RX](#) [M8-10R/SX](#)