

In-X

Interchangeable Magnification
Patent Pending

Interchangeable
Lenses

Choose Your
Magnification

64 SMD
LEDs

20,000 Hour
Lifespan

Brightness
Controls

Touch Sensitive
Buttons

Spring
Balanced Arm

No Pinch
Hazards

The Next Level

X - change lenses
- pand magnification
- tended flexibility

Easy Lens Replacement, No Tools Required



Remove Lens



Insert New Lens



Interchangeable Lens
5 diopter, 2.25x
magnification

Brightness Control
touch sensitive buttons

Covered Spring
Balanced Arm

no pinching hazards or
exposed springs

Tension Control Knob
adjusts 360°
rotatable head


Decorative Stainless
Steel Ring

Xplore the Possibilities

Crystal clear lenses provide up to 4.75x magnification



5 Diopter (2.25x)
(included)

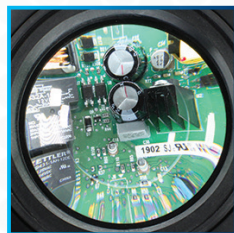

8 Diopter (3x)
(sold separately)



12 Diopter (4x)
(sold separately)



15 Diopter (4.75x)
(sold separately)

IN-X MAGNIFYING LAMP

Item #	26501-LED-INX
Illumination	64 adjustable SMD LEDs
Arm Reach	Max 36in
Lumens	Max 950lm
LED Color Temperature	6500K
Power Consumption	1-10W
Included Lens	26501-INX-RL5D, 5 diopter lens (2.25x magnification)
Power Supply	Input: 100-240V ~ 50/60Hz -0.45A Output: 26.0V / 500mA
Package Contents	In-X Magnifying Lamp, heavy duty table clamp w/2in opening, power supply, 5 diopter lens (additional lenses sold separately)

ITEM

PRODUCT NAME

26501-LED-INX	In-X Magnifying Lamp 5 Diopter
26501-INX-RL8D	In-X 8 Diopter Lens (3x magnification)
26501-INX-RL5D	In-X 5 Diopter Lens (2.25x magnification)
26501-INX-RL12D	In-X 12 Diopter Lens (4x magnification)
26501-INX-RL15D	In-X 15 Diopter Lens (4.75x magnification)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aven:](#)

[26501-INX-RL12D](#) [26501-INX-RL15D](#) [26501-LED-INX](#) [26501-INX-RL5D](#) [26501-LED-INX-15D](#) [26501-INX-RL8D](#)