




# STEALTH PLIERS




**CHAIN NOSE 5" WITH SMOOTH JAWS**

**ITEM #**  
**10841**

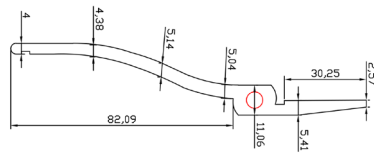


**SHORT NEEDLE NOSE 5" WITH SMOOTH JAWS**

**ITEM #**  
**10845**

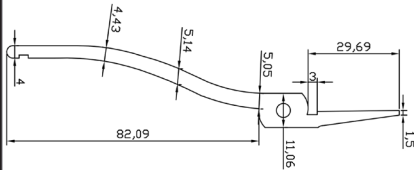


**ROUND NOSE 5" WITH SMOOTH JAWS**

**ITEM #**  
**10846**

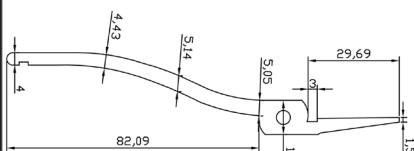


**FLAT NOSE 5" WITH SMOOTH JAWS**

**ITEM #**  
**10847**

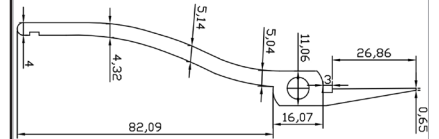


**FLAT NOSE 6" WITH SMOOTH JAWS**

**ITEM #**  
**10848**

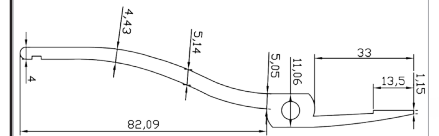


**LONG NEEDLE NOSE 6" WITH SERRATED JAWS**

**ITEM #**  
**10849**

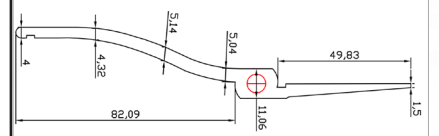

**BENT NOSE 6" WITH SMOOTH JAWS**

**ITEM #**  
**10850**

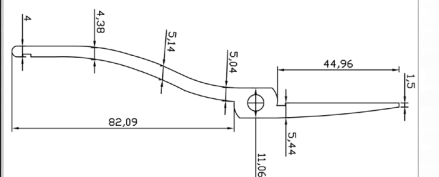



# STEALTH PLIERS



## **Machined Stainless Steel**

- Precise Tip Alignment
- Exceptional Durability



## **Ultra-Responsive Dual Leaf Springs**

- Reduce hand fatigue for repeated use



## **ESD Safe Grips**

- Ergonomic comfort grips
- ESD Safe



## **7 Models Available**

- Seven tip styles ideal for a variety of applications

## **Heavy-Duty Precision Pliers**

Made from machined stainless steel, Aven's Stealth Pliers are designed for heavy-duty use. Featuring screw joint construction for maximum durability, ensuring precise alignment for the life of the pliers. Ultra-responsive leaf springs provide easy opening and closing of the pliers for reduced hand fatigue during repetitive use. ESD safe, ergonomic hand grips provide protection against static build up and feel comfortable for all hand sizes. Ideal for projects that include forming, bending and precision assembly.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aven:](#)

[10846](#) [10841](#) [10845](#) [10847](#) [10848](#)