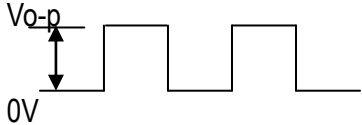


1. Specifications

AP-1201B-LF



Items		Units	Specifications		Conditions
01	Rated Voltage	Vo-p	1.5		
02	Operating Voltage	Vo-p	1.0 ~ 2.0		
03	Comsumption Current	mA (Max)	Mean	25	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak	75	
04	Direct Current Resistance	Ohm	42±6.3		
05	Sound Output	dBA (min)	75		Distance at 10cm, applying rated voltage, rated frequency square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2048		

REV NO.

REVISION NOTE

APPROVAL

DATE

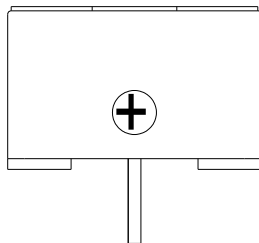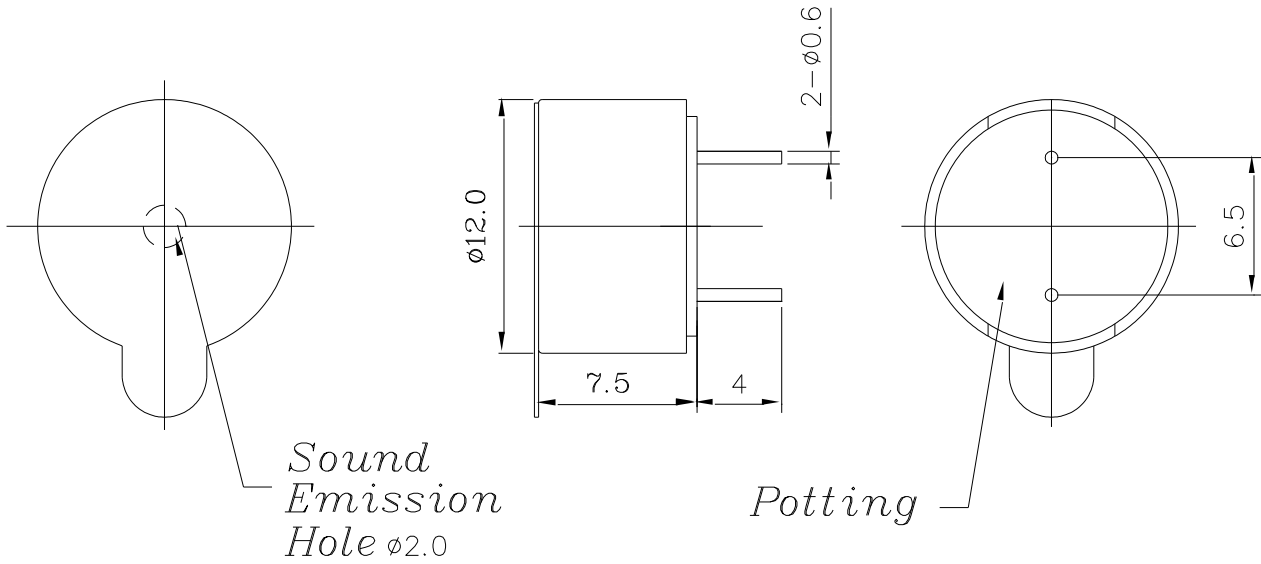

TITLE: SOUND TRANSDUCER DIMENSIONS

DRAWN: Jack

2003/11/17

SCALE: 3:1

SHEET: 1 OF 1

PART NO. AP-1201B-LF

1

DESIGNED: R&D OF AAT

CHECKED:

APPROVAL:

DWG NO. DTE-1098

REV

MATERIAL: PPO

UNITS: mm

TOLERANCE ± 0.5

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AP-1201B-LF](#)