 
 



1. SPECIFICATION

AZ-4228S-W3S

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	1.5~ 20	
03	Consumption Current	mA (Max)	10	Rated Voltage
04	Resonant Frequency	Hz	2800± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	96	Distance at 30cm Rated Voltage / Resonant Frequency

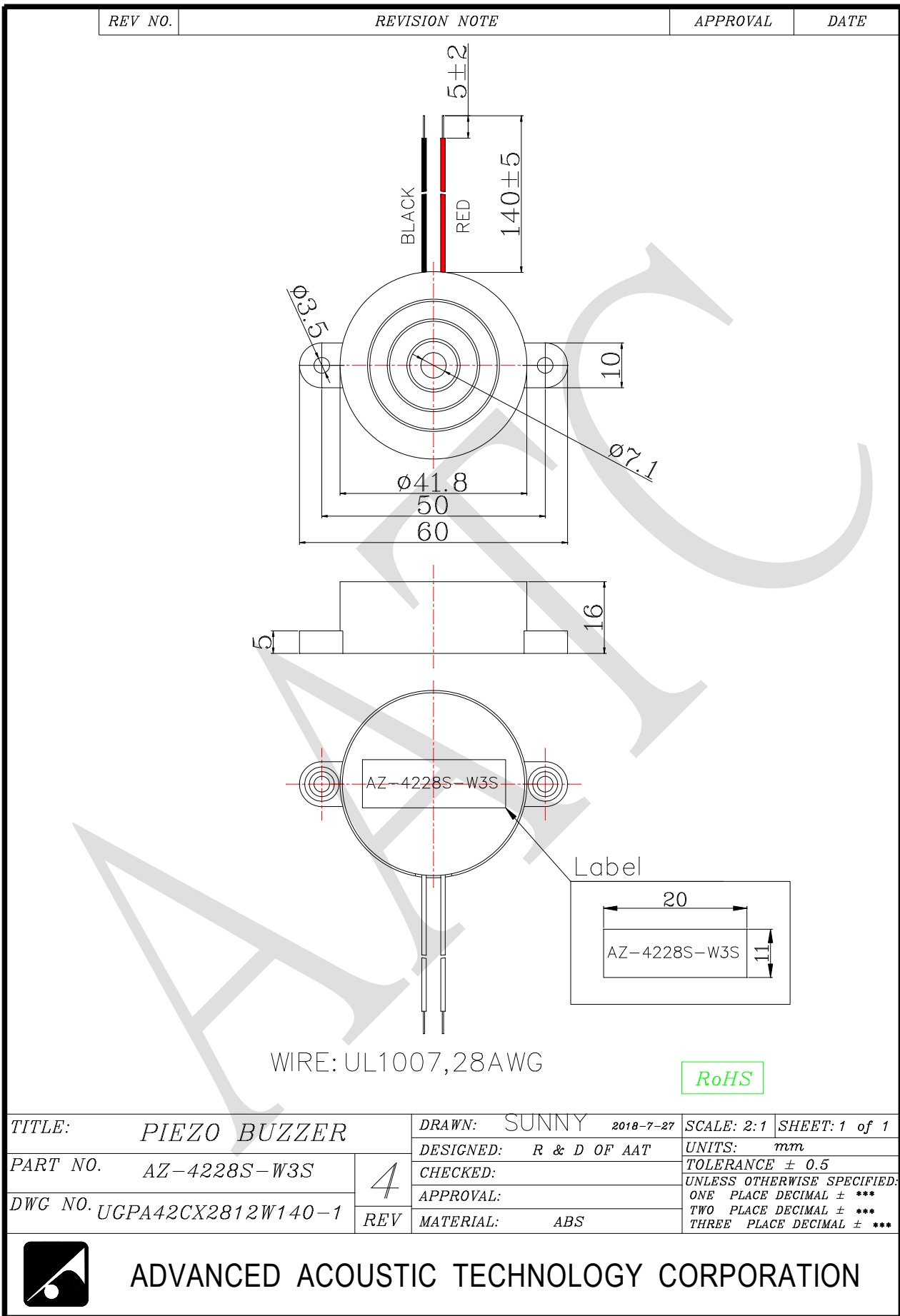

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4228S-W3S