

1. SPECIFICATION

AZ-2429S-P1-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	8~ 16	
03	Rated Current	mA(Max)	12	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	100	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	2900	Rated Voltage
06	Resonant Frequency	Hz	2900± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

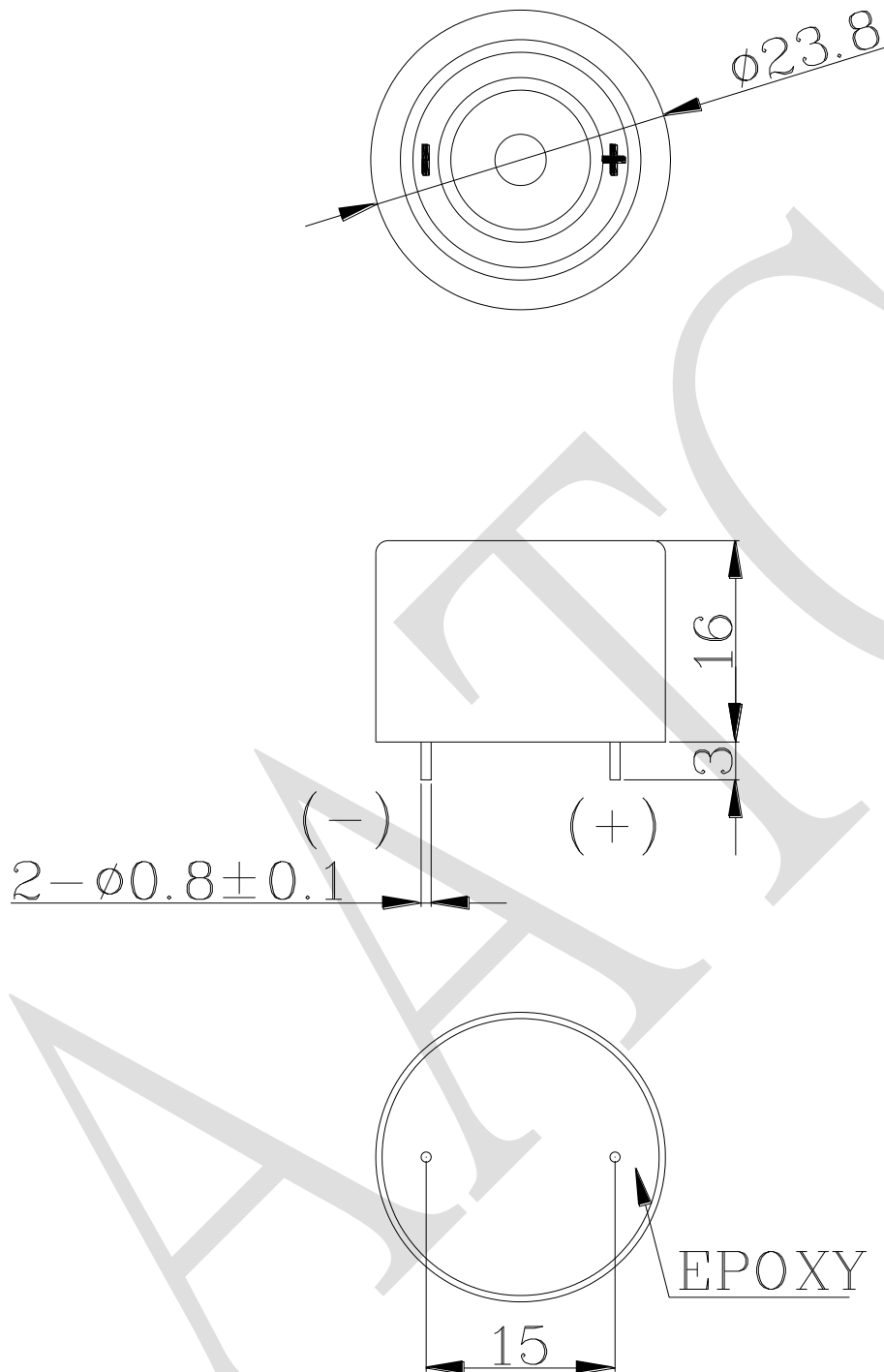

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Jerry <i>2013/10/25</i>	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-2429S-P1-LF</i>	<i>2</i>			
DWG NO. <i>UGPM24DX2912P3</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL \pm ***	
REV		MATERIAL: <i>ABS</i>	TWO PLACE DECIMAL \pm ***	
		THREE PLACE DECIMAL \pm ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-2429S-P1-LF