


1. SPECIFICATION


AZ-2337S-P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3~ 16	
03	Rated Current	mA(Max)	8	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3700	Rated Voltage
06	Resonant Frequency	Hz	3700± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

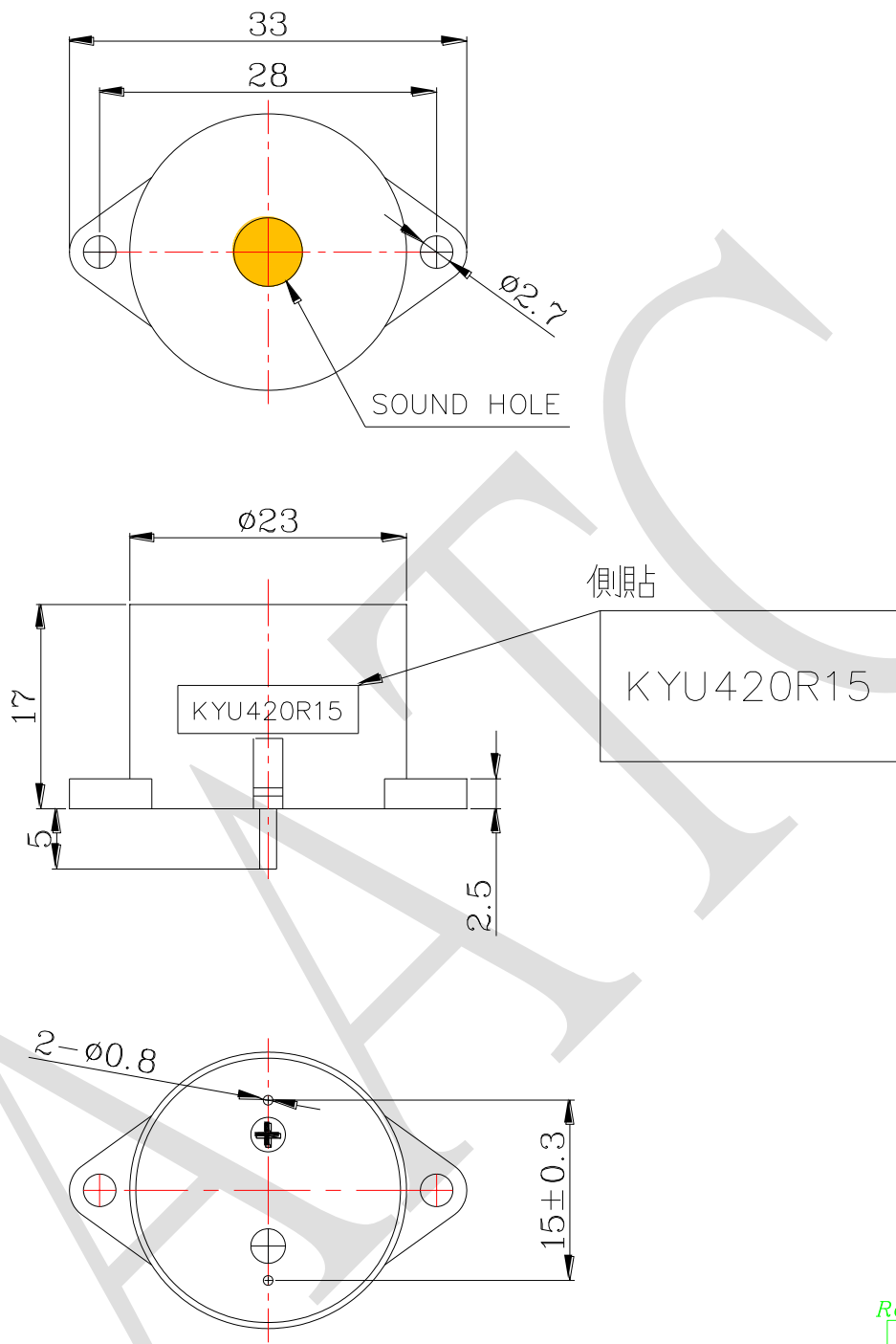

 RoHS



TITLE: <i>PIEZO BUZZER</i>		DRAWN: Jary	2012/11/20	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-2337S-P</i>		DESIGNED: <i>R & D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>UGPA23FX3712P-BSn</i>		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>ABS</i>		ONE PLACE DECIMAL \pm ***	
	2			TWO PLACE DECIMAL \pm ***	
	REV			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2337S-P](#)