


1. SPECIFICATION

AZ-2335S-1P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	1.5 ~ 28	
03	Rated Current	mA(Max)	10	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3500	Rated Voltage
06	Resonant Frequency	Hz	3500 ± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

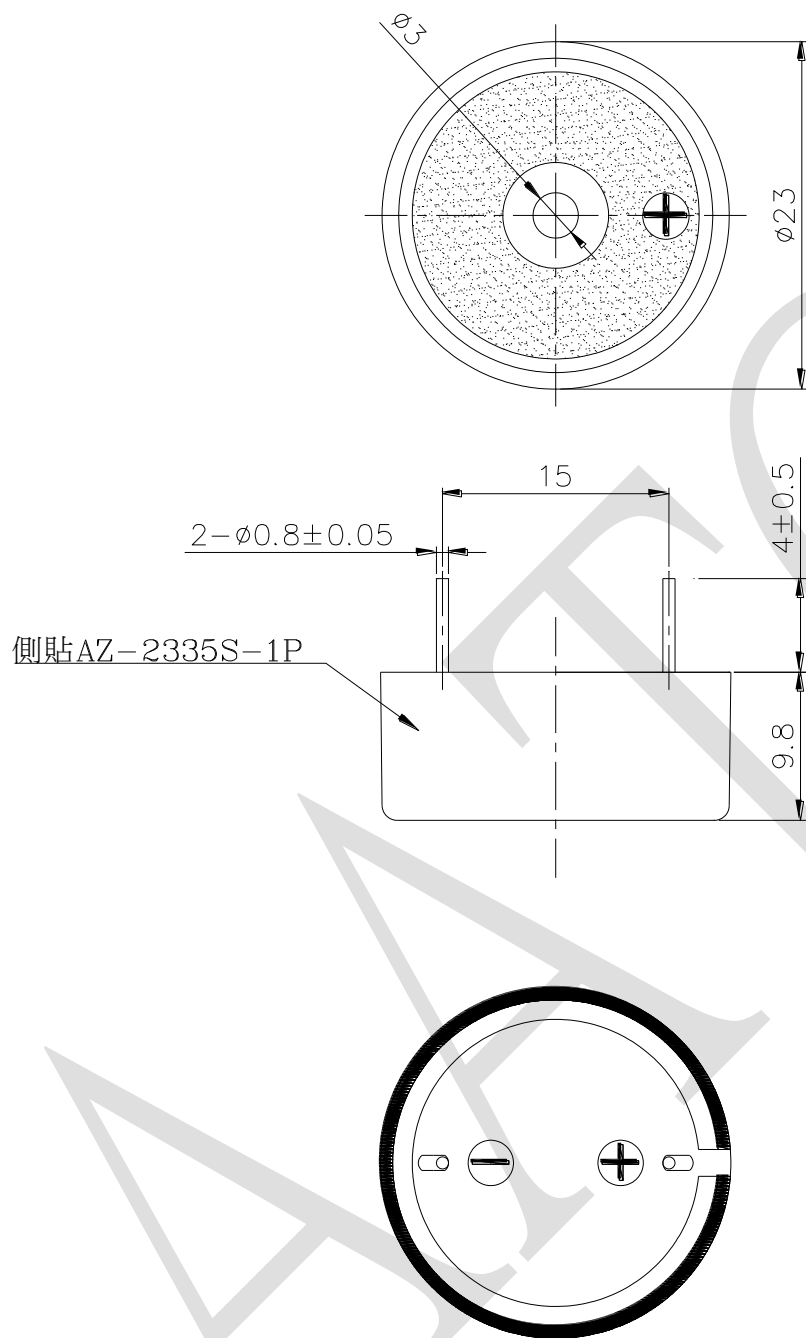

RoHS

TITLE:	PIEZO BUZZER	DRAWN:	Zack	2013/01/08	SCALE: 2:1	SHEET: 1 of 1
PART NO.	AZ-2335S-1P	DESIGNED:	R & D OF AAT		UNITS:	mm
		CHECKED:			TOLERANCE	± 0.5
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:	
DWG NO.	UGPA23GX3512P4.0				ONE PLACE DECIMAL \pm	***
					TWO PLACE DECIMAL \pm	***
					THREE PLACE DECIMAL \pm	***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2335S-1P](#)