 


1. SPECIFICATION

AC-12T12B



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	6 ~ 15	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	140±21	
06	Rated Frequency	Hz	2400	

REV NO.




REVISION NOTE

APPROVAL

DATE

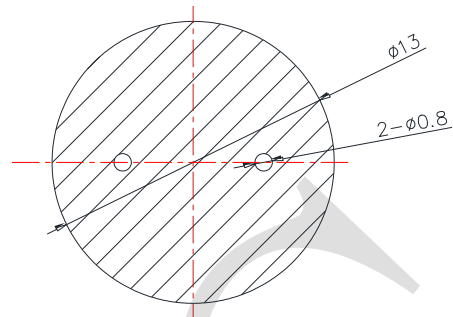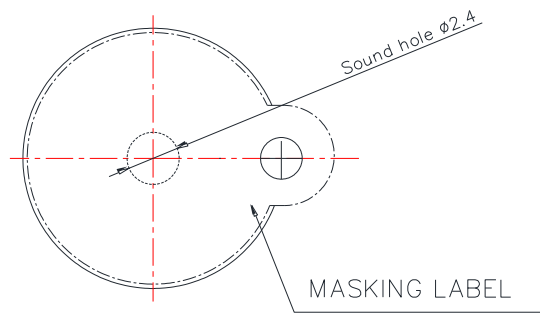

RECOMMEND PCB LAYOUT

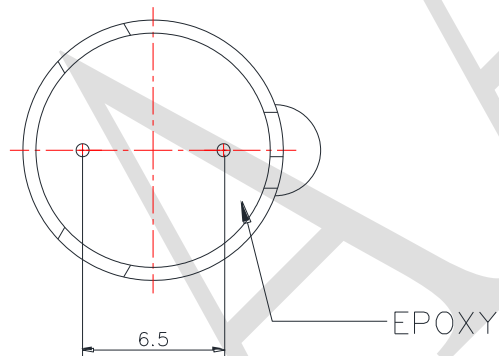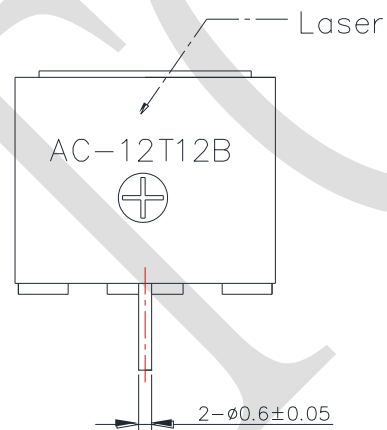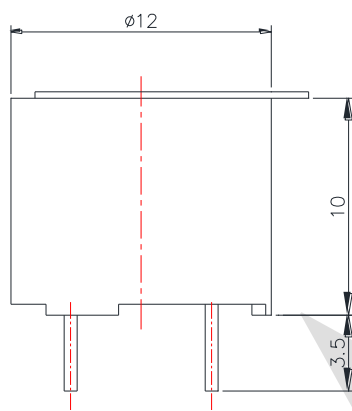

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Hank

2020-02-19

SCALE: 4:1

SHEET: 1 of 1

PART NO. AC-12T12B

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

DWG NO. UGC1212G-05P3.5B-1

1

REV

MATERIAL: PBT



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-12T12B](#)