
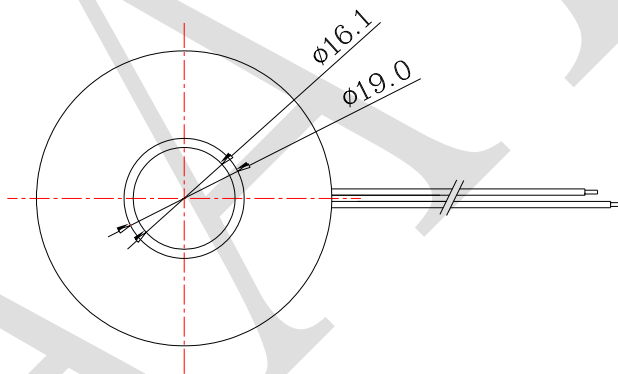
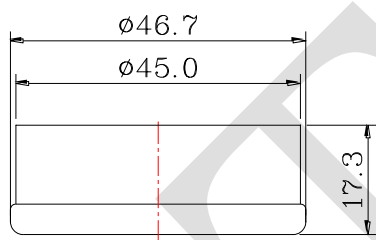
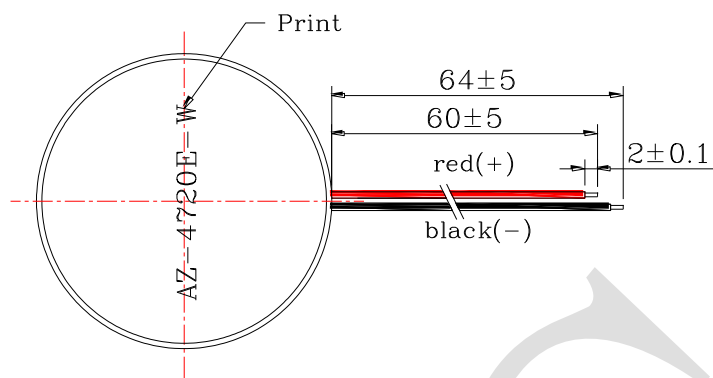


1. SPECIFICATION

AZ-4720E-W-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	 Square wave 1/2 duty.
02	Operating Voltage	V	1~ 30	
03	Consumption Current	mA (Max)	30	
04	Sound pressure level (Distance at 30cm)	dB(A) (Min)	90	Rated voltage, rated frequency.
05	Capacitance	pF	150000±30%	At 120Hz
06	Rated Frequency	Hz	2500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



WIRE: UL 1571. AWG28#

TITLE:	PIEZO SPEAKER	DRAWN:	Moose	2018-04-20	SCALE: 1:1	SHEET: 1 OF 1
PART NO.	AZ-4720E-W-LF	DESIGNED:	R & D OF AAT	CHECKED:	UNITS:	mm
DWG NO.	AZ-4720E-W	APPROVAL:	MATERIAL:	ABS	TOLERANCE	± 0.5
					UNLESS OTHERWISE SPECIFIED	
					ONE PLACE DECIMAL \pm	***
					TWO PLACE DECIMAL \pm	***
					THREE PLACE DECIMAL \pm	***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4720E-W-LF