
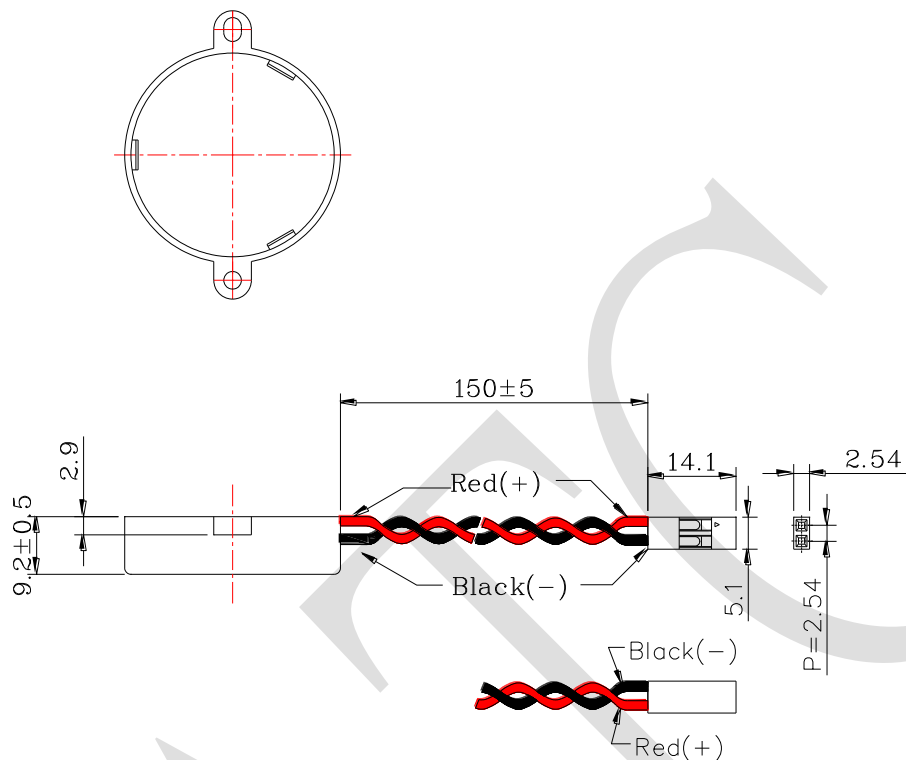


1. SPECIFICATION

AZ-3511E-C4

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	<div><p>Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	1~ 30	
03	Consumption Current	mA (Max)	5	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	81	Rated voltage, rated frequency.
05	Capacitance	pF	43000±30%	At 120Hz
06	Rated Frequency	Hz	1100± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



CONNECTOR : Equivalents to 杜邦 2541-1h-2  
WIRE: UL1095 ,AWG28

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Moose</i> 2018-01-17	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-3511E-C4</i>	2 REV	DESIGNED: <i>R &amp; D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>UGPA35C1110WC150</i>		CHECKED:	TOLERANCE $\pm 0.5$	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-3511E-C4