 

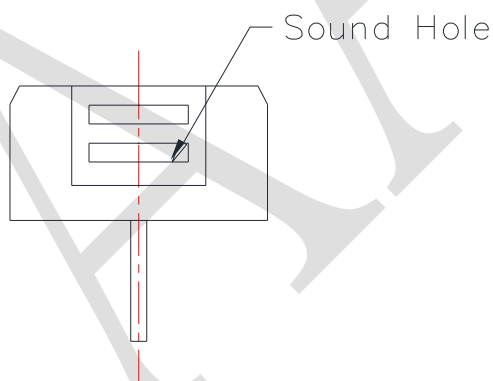
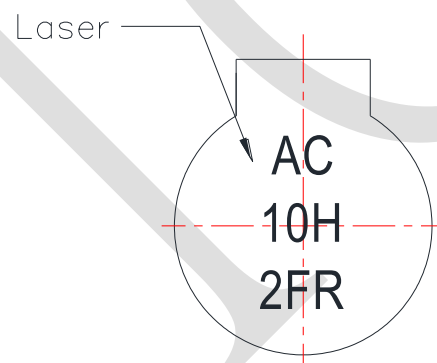
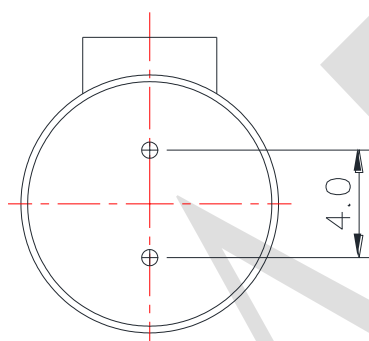
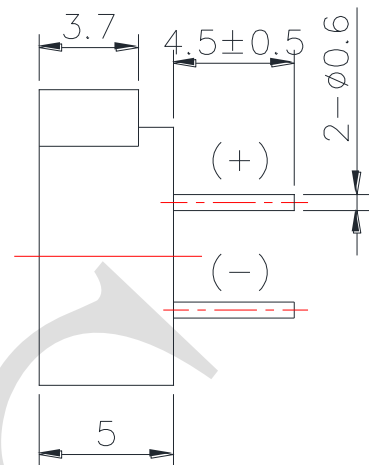


1. SPECIFICATION

AC-10H2FR

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	<div><p>Standard state, standard drive circuit. Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	90	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	5.5±1	
06	Rated Frequency	Hz	4000	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

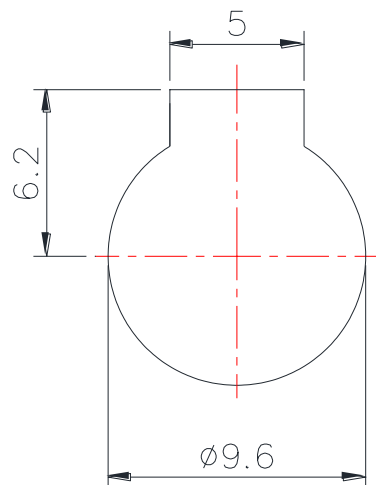

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Hank	2020/02/19	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-10H2FR	1	DESIGNED: R&D OF AAT		UNITS: mm	TOLERANCE ± 0.5
DWG NO. UGCM0901BPF1		CHECKED:		UNLESS OTHERWISE SPECIFIED:	
		APPROVAL:		ONE PLACE DECIMAL ± ***	
	REV	MATERIAL: NORYL		TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-10H2FR](#)