

1. SPECIFICATION

APD-1603-PA


| ITEM | | UNITS | SPECIFICATIONS | CONDITIONS |
|------|---|----------|----------------|----------------------------------|
| 01 | Rated Voltage | V | 3 | Vp-p (Square Wave) |
| 02 | Operating Voltage | V | 1~25 | |
| 03 | Rated Current | mA(Max) | 3 | Rated Voltage |
| 04 | Sound pressure level (Distance at 10cm) | dBA(Min) | 70 | Rated Voltage Rated Frequency |
| 05 | Resonant Frequency | Hz | 4000± 500 | Rated Voltage |
| 06 | Capacitance | pF | 14000±30% | At 100Hz |

REV NO.

REVISION NOTE

APPROVAL

DATE

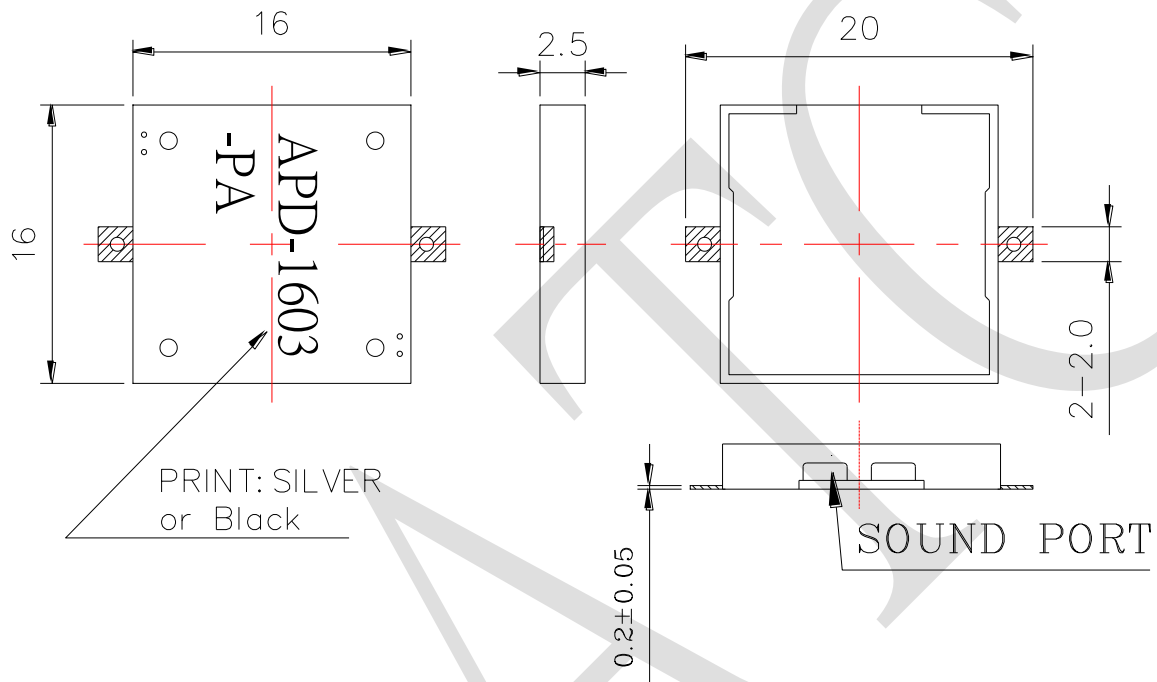

RoHS

TITLE: SMD PIEZO BUZZER

DRAWN: Moose

2019-01-04

SCALE: 2:1

SHEET: 1 of 1

PART NO. APD-1603-PA

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. SMD-160025H-03040T

3

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: LCP

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[APD-1603-PA](#)