
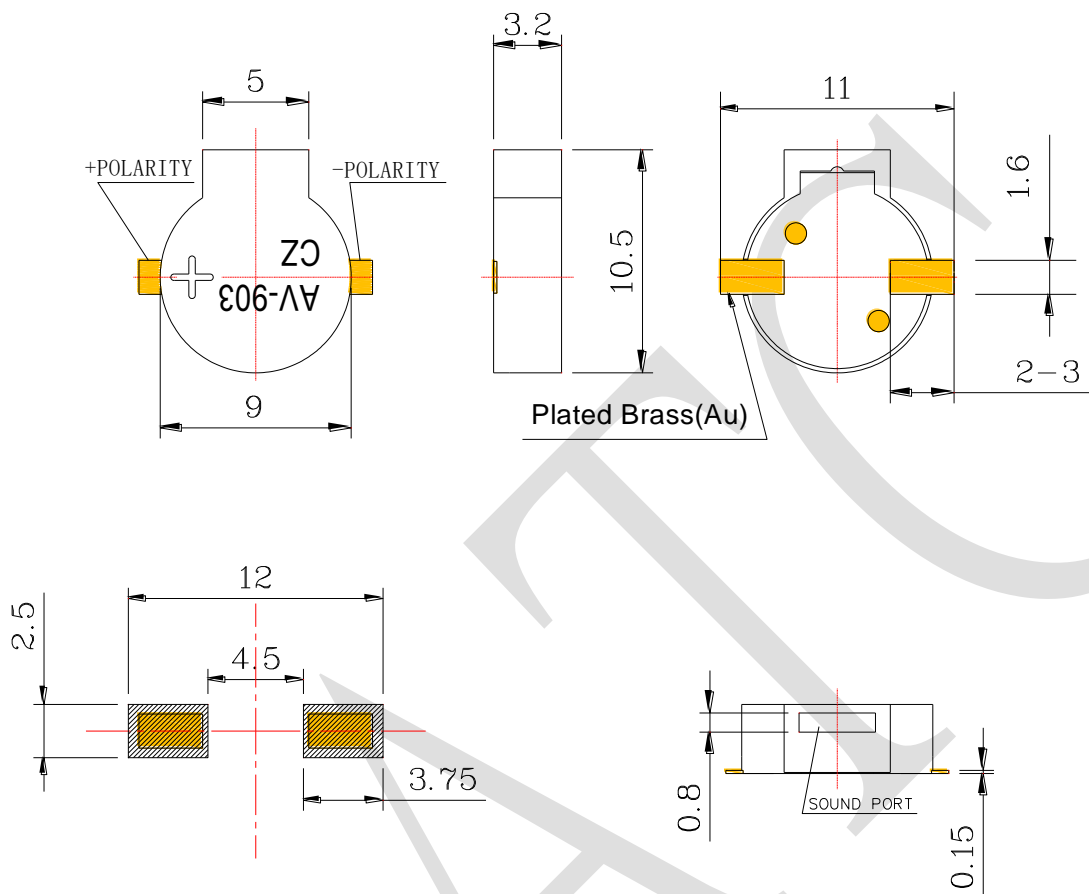


1. SPECIFICATION

AV-903-CZ

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA (Max)	Mean : 100	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 300	
04	Direct Current Resistance	Ω	15 ± 3	
05	Sound Output (Distance at 10cm)	dBA (Min)	80	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2730	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



Recommend P.C.B LAYOUT

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Zack	2013/10/01	SCALE: 1:1	SHEET: 1 : 1
PART NO. AV-903-CZ	2	DESIGNED: R & D OF AAT		UNITS: mm	
		CHECKED:		TOLERANCE ± 0.5	
DWG NO. SMD-090032H-03027J		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: LCP		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)
[AV-903-CZ](#)