


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5.0	Vp-p
02	Operating Voltage	V	3 ~ 7	
03	Consumption Current	mA (Max)	Mean : 85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 255	
04	Direct Current Resistance	$\Omega$	40 $\pm$ 3	
05	Sound pressure level (Distance at 10cm )	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2731	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

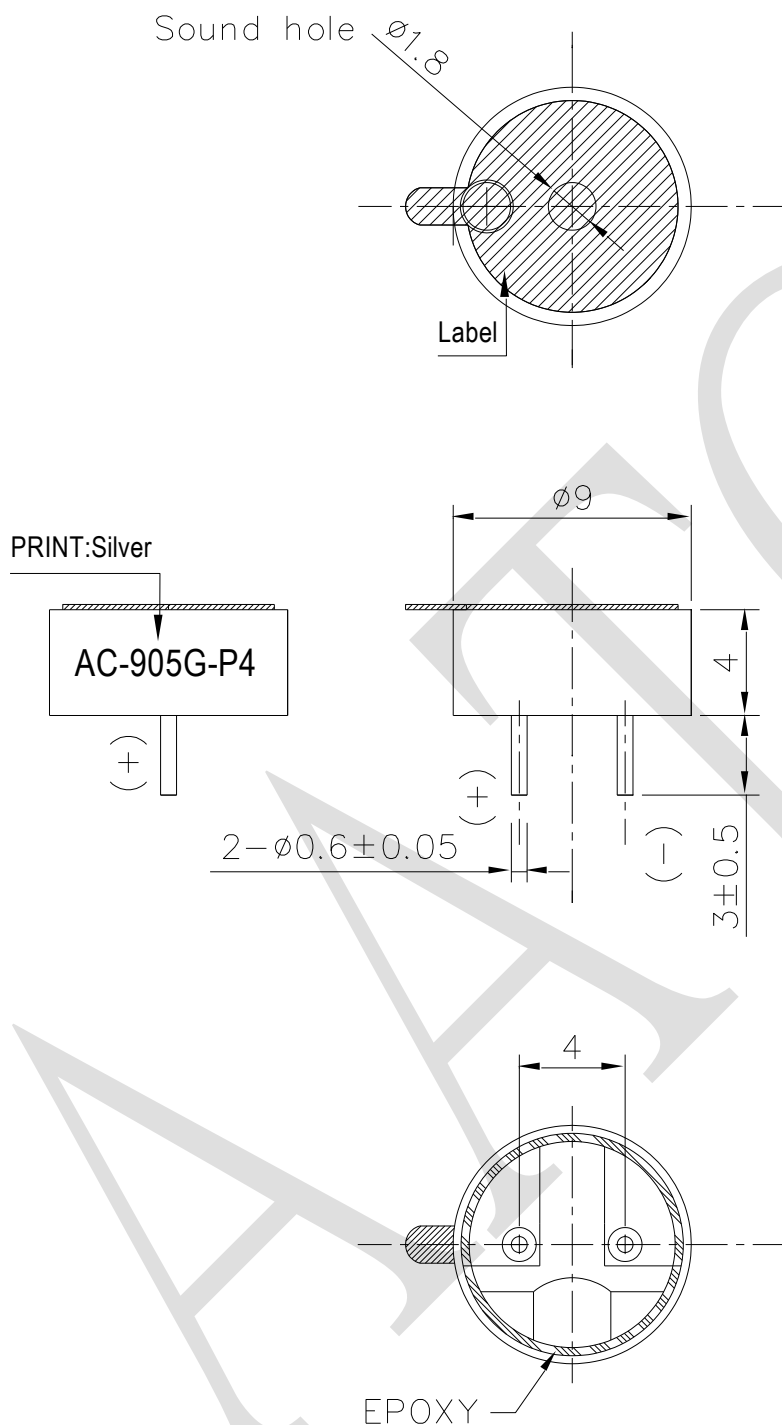

RoHS

TITLE: SOUND TRANSDUCER DIMENSIONS		DRAWN: Jerry	2012/06/29	SCALE: 3/1	SHEET: 1 OF 1
PART NO.	AC-905G-P4-1	DESIGNED:	R&D OF AAT	UNITS:	mm
DWG NO.	HS-110810	CHECKED:		TOLERANCE	$\pm 0.3$
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL:	PBT	ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-905G-P4-1](#)