

1. SPECIFICATIONS

AMF-O60F38-NW1

01	Electret's Type	Foil type
02	Sensitivity	-38±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	100 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB
11	Sound Pressure Level	110 dB



REV NO.

REVISION NOTE

APPROVAL

DATE

FILTER

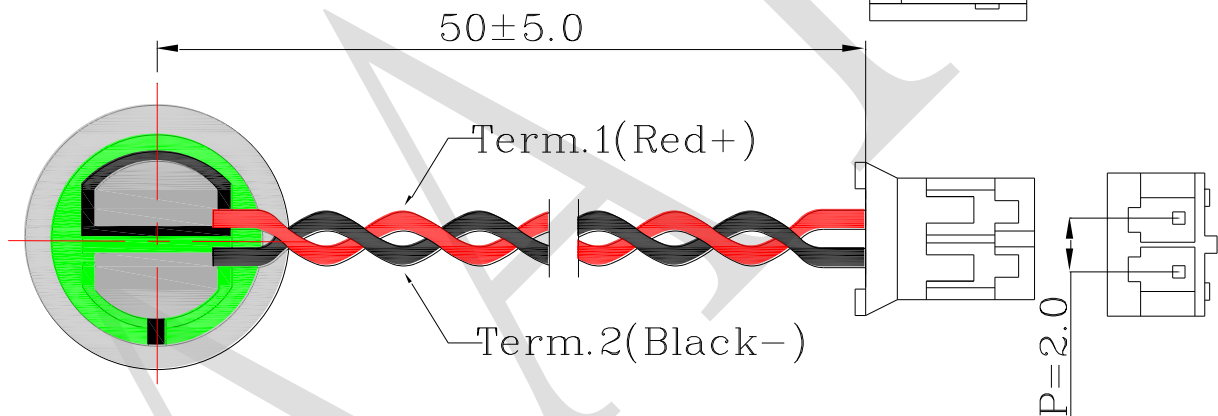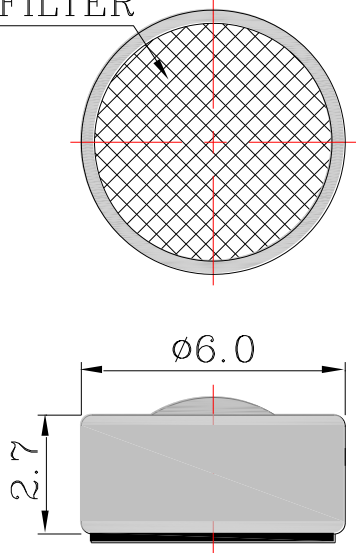

WIRE: UL 1571.AWG30#
CONNECTOR: Equivalent to JST PHR-2

RoHS

TITLE: MICROPHONE

DRAWN: Jerry 2013/04/19

SCALE: 5:1 SHEET: 1 of 1

PART NO. AMF-060F38-NW1

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO. F6027AL-SD-D50 6986

2

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: *****

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMF-O60F38-NW1](#)