

## 1. SPECIFICATION

AZ-1640E-WV9


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 30	
03	Rated Current	mA(Max)	7	Rated Voltage
04	Sound pressure level (Distance at 10cm )	dBA(Min)	80	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000 ± 300	Rated Voltage
06	Capacitance	pF	15000±30%	At 1K Hz

REV NO.

REVISION NOTE

APPROVAL

DATE

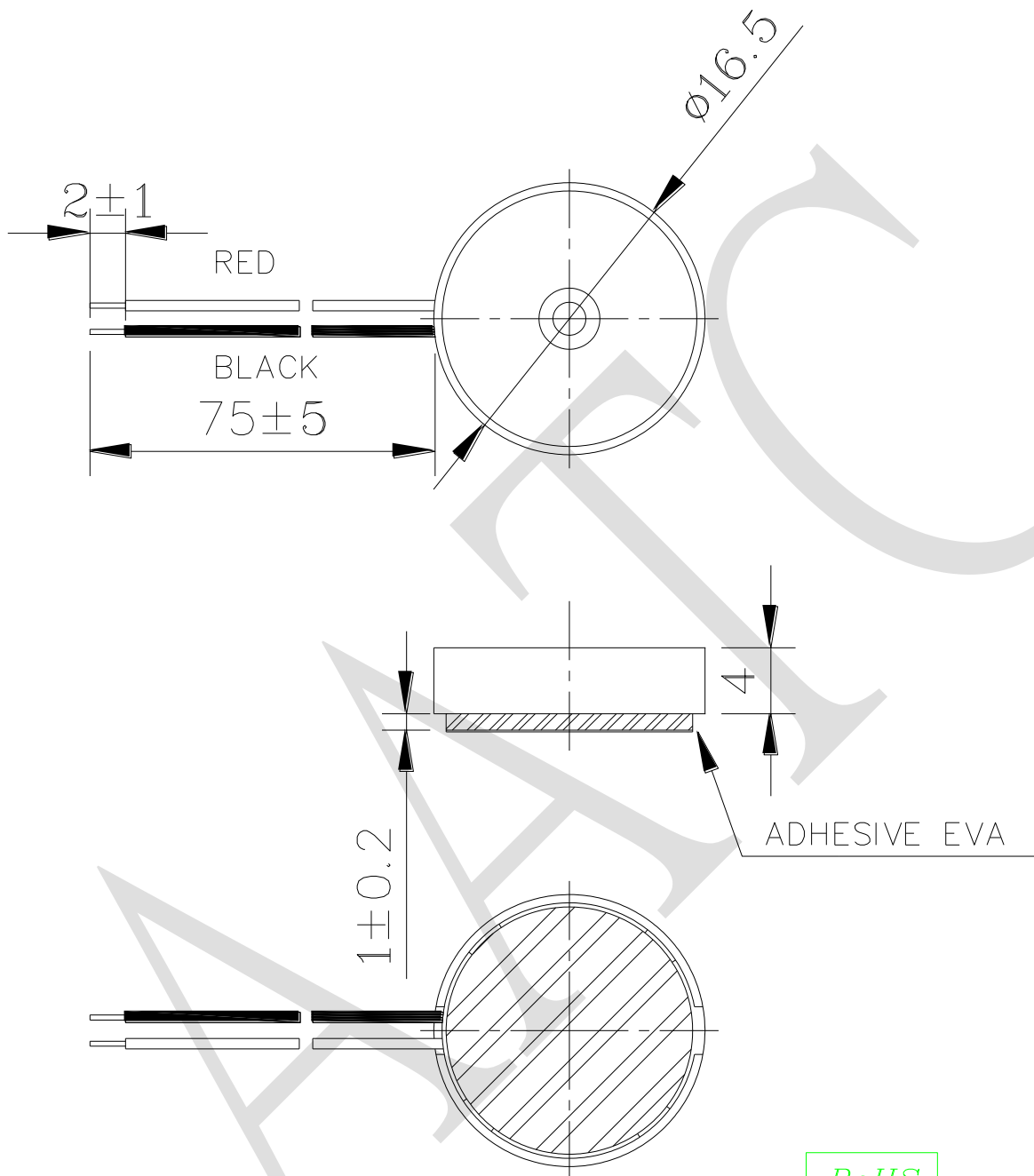

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <b>Zack</b> 2013/03/21		SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1640E-WV9</i>	2	DESIGNED: <i>R&amp;D OF AAT</i>		UNITS: <i>mm</i>	
		CHECKED:		TOLERANCE $\pm 0.3$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
DWG NO. <i>UGPA17A4009W75T</i>	REV	MATERIAL: <i>ABS</i>		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1640E-WV9](#)