


1. SPECIFICATION

AZ-1340E-P14

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1 ~ 30	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	75	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000 ± 300	Rated Voltage
06	Capacitance	pF	15000 ±30%	At 120 Hz

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

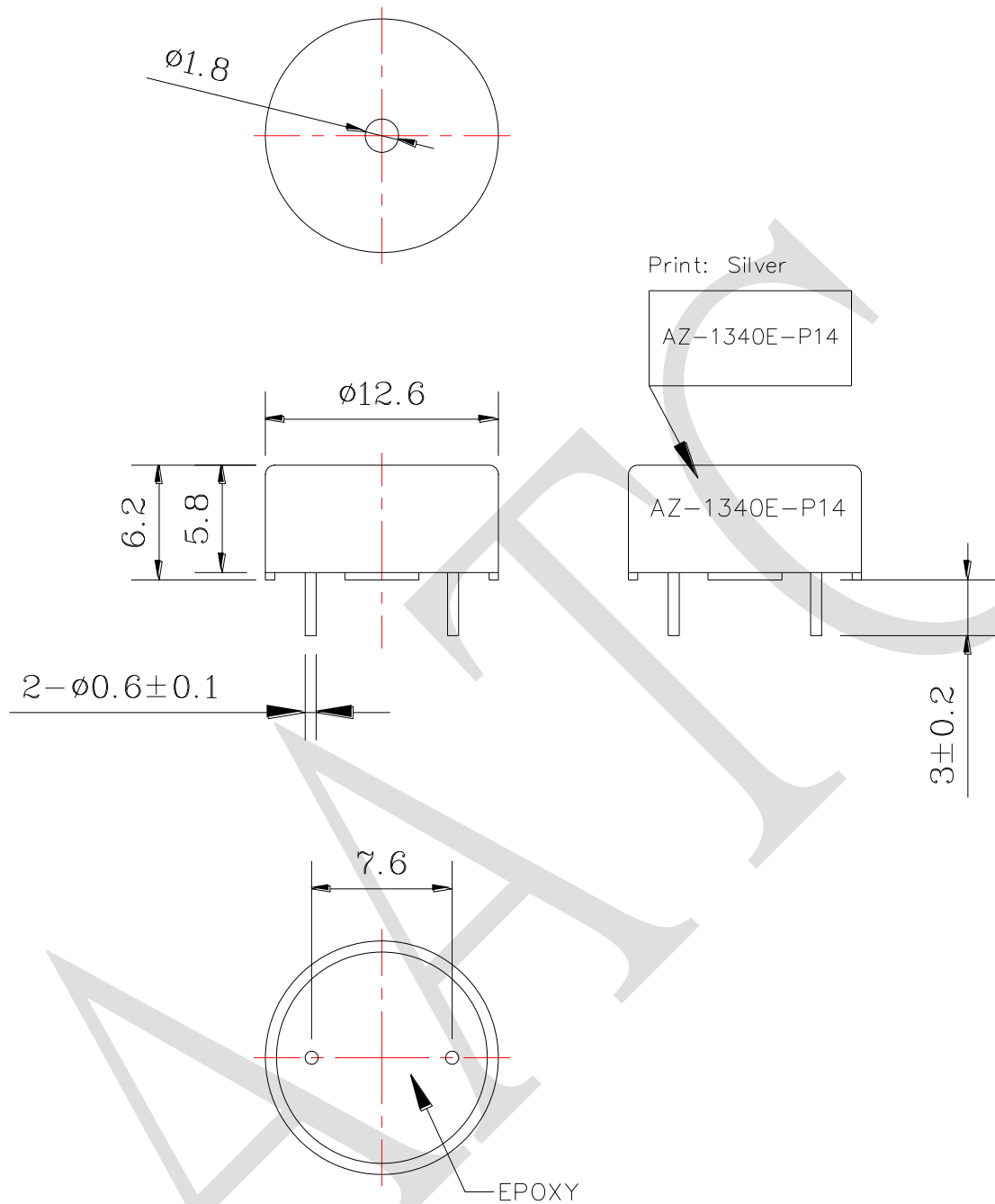

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zack	2012/06/29	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1340E-P14</i>	2	DESIGNED: <i>R&D OF AAT</i>	UNITS: <i>mm</i>		
DWG NO. <i>LPT1360E-T0-03-4.0-15-7.6-R</i>		CHECKED:	TOLERANCE ± 0.5		
REV		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: <i>PPO</i>	ONE PLACE DECIMAL \pm ***		
			TWO PLACE DECIMAL \pm ***		
			THREE PLACE DECIMAL \pm ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1340E-P14](#)