

1. SPECIFICATIONS

AMF-O97A44-1CWH

01	Electret's Type	Foil type
02	Sensitivity	-44±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	100 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB
11	Sound Pressure Level	110 dB

REV NO.

REVISION NOTE

APPROVAL


DATE

FILTER

Wire: UL1571,AWG28#

Holder: DD-EQ-JTE13-04.

Connector:Equivalent to JST PHR-2

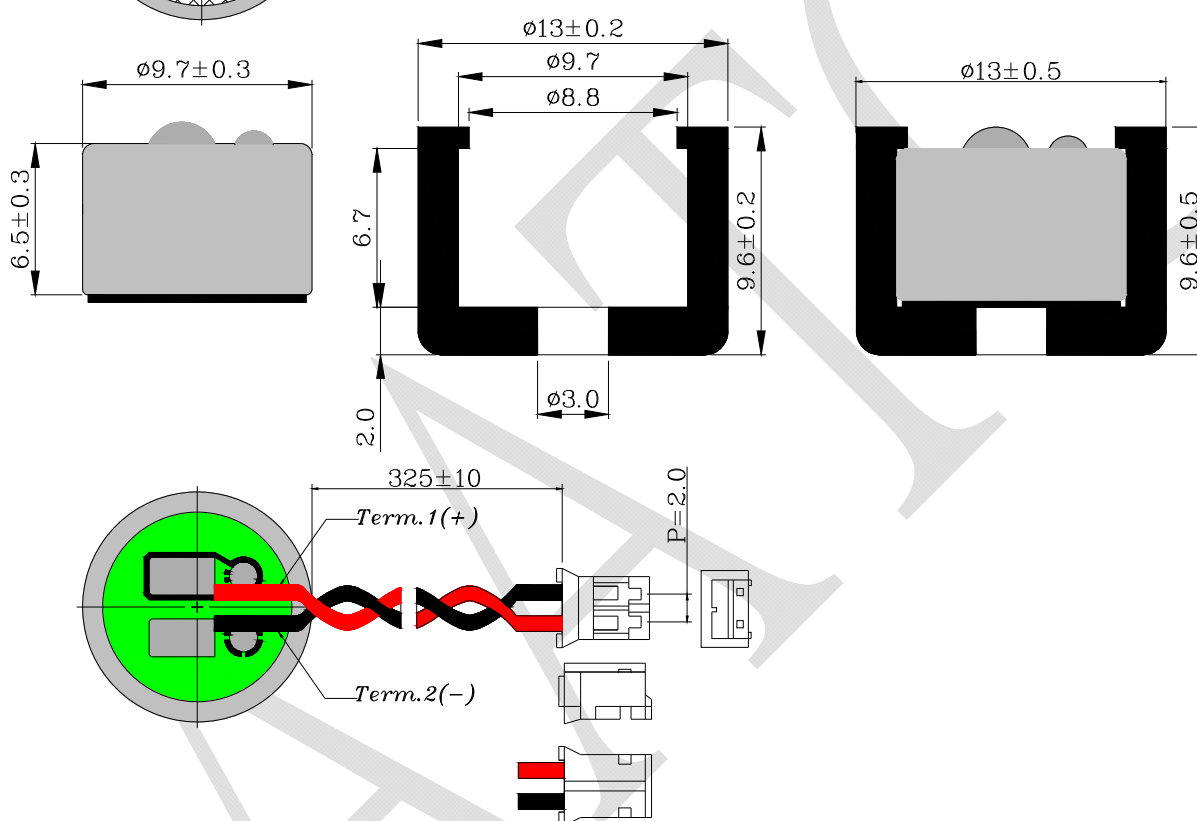

RoHS

TITLE: MICROPHONE		DRAWN: Zack	2016/07/20	SCALE: 4:1	SHEET: 1 of 1
PART NO. AMF-097A44-1CWH	1	DESIGNED: R & D OF AAT	UNITS: mm		
DWG NO. F9765AL-SNRV-D330-M 11583		CHECKED:	TOLERANCE ± 0.3		
	REV	APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: AL	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMF-O97A44-1CWH](#)