 


1. SPECIFICATION

AC-903Q-P12


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	Mean : 80	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 240	
04	Direct Current Resistance	Ω	15 \pm 3	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	82	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2731	

REV NO.

REVISION NOTE

APPROVAL

DATE

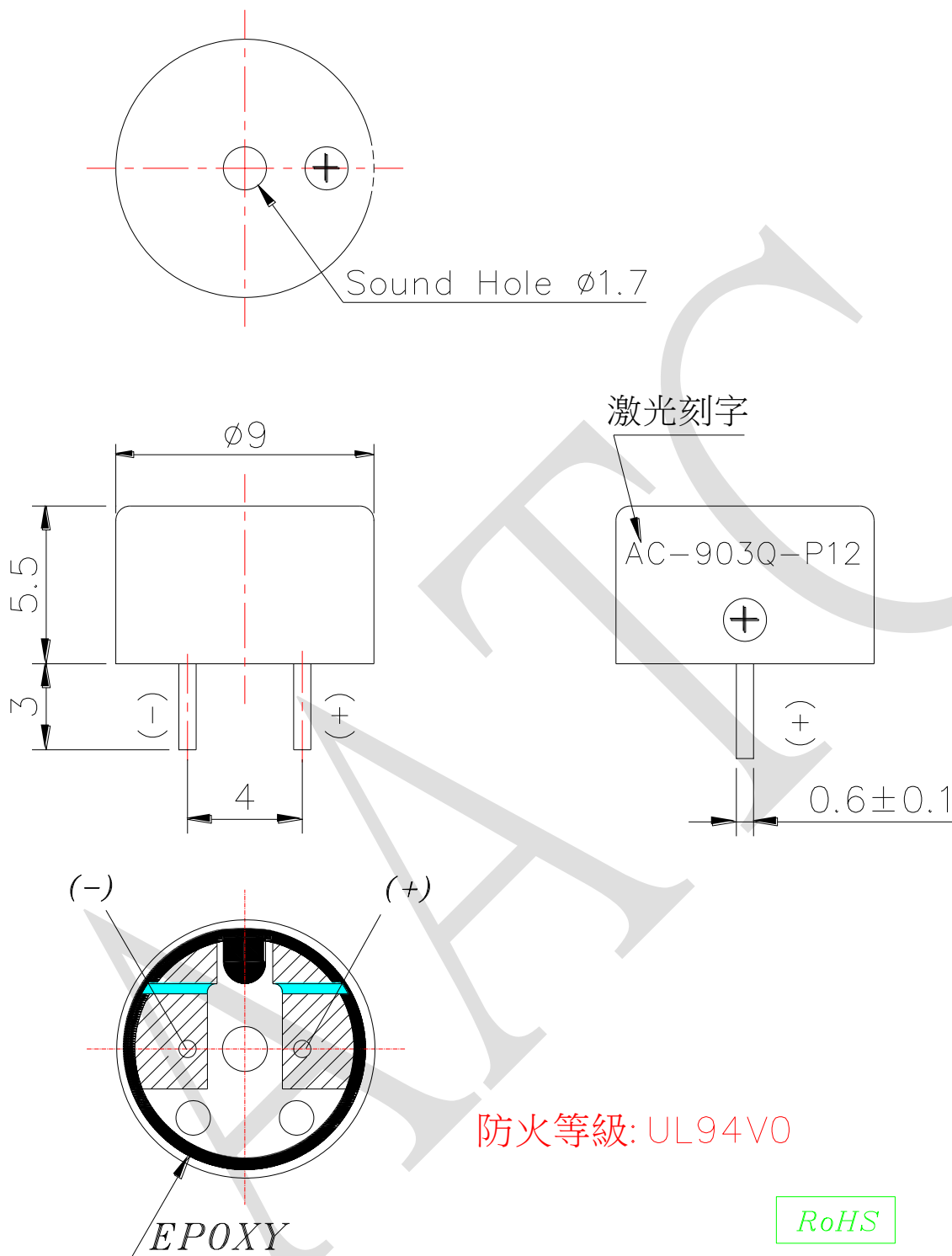

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose

2015/08/14

SCALE: 4:1

SHEET: 1 of 1

PART NO. AC-903Q-P12

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. UGCM0903EP3.0D-82

1

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: PBT

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-903Q-P12](#)